

DMX-CONTROLLED RGBW LED BAR WITH 6 LED & REMOTE CONTROL

LEDBAR6-RC


Compact LED bar fitted with 4-in-1 RGBW LEDs.

- 6 x 8W 4-in-1 RGBW LED
- 8 / 4-1 / 4 / 3 / 2 DMX channels
- Stroboscope 0-20Hz
- Auto, master-slave, DMX, sound or remote-controlled operation
- 4 control buttons with LED display
- Remote control

EAN 5420047136428
CODE 16-2097

SPECIFICATIONS TECHNIQUES

Power supply	AC100~240V 50/60Hz
Consumption	48W
DMX channels	8 / 4-1 / 4 / 3 / 2
Light source	6 x 8W RGBW LED 4-in-1
Beam angle	25°
Fuse	0.5A
Dimensions	2.5kg
Weight	605 x 145 x 120mm

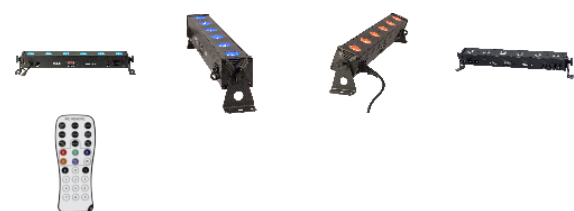

LOGISTICS VALUES

Code EAN 14	54200471364286
Poids brut	gr / 0 kg
Poids net	gr / 0 kg

