


**KEMET Part Number: ESD-FPL-13**  
(UECESDFPL13000)

KEMET, ESD-FPL, EMI Cores, Noise Suppression

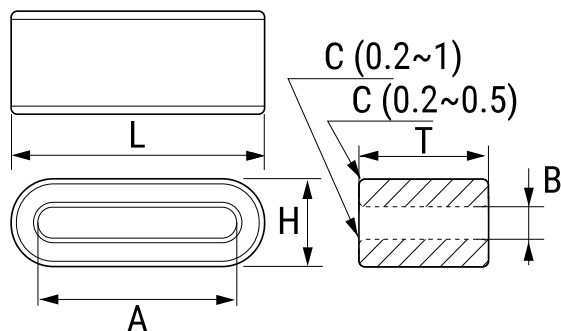

**Dimensions**

|          |                 |
|----------|-----------------|
| <b>L</b> | 23.8mm +/-0.7mm |
| <b>T</b> | 15mm +/-0.6mm   |
| <b>H</b> | 6.3mm +/-0.5mm  |
| <b>A</b> | 18.8mm +/-0.5mm |
| <b>B</b> | 1.1mm +/-0.50mm |

**Packaging Specifications**

|                            |           |
|----------------------------|-----------|
| <b>Packaging:</b>          | Tray, Box |
| <b>Packaging Quantity:</b> | 840       |
| <b>Weight:</b>             | 9.3 g     |

**General Information**

|                          |  |
|--------------------------|--|
| <b>Series:</b>           | ESD-FPL                                    |
| <b>Style:</b>            | Flat - Solid                               |
| <b>Cable Type:</b>       | Flat Cable                                 |
| <b>Description:</b>      | EMI Core Solid, For Flat Cables, Bare Type |
| <b>RoHS:</b>             | Yes  |
| <b>Applicable Cable:</b> | 13 Core                                    |
| <b>Materials:</b>        | Ni-Zn                                      |

**Specifications**

|                             |                         |
|-----------------------------|-------------------------|
| <b>Temperature Range:</b>   | -25/+85C                |
| <b>Effective Frequency:</b> | 300 MHz (FM Band Range) |