


KEMET, SSHB10HS, AC Line Filters, Dual Mode, 1100 uH

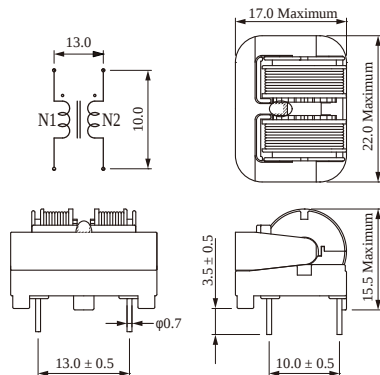

Dimensions

L	22mm MAX
T	17mm MAX
H	15.5mm MAX
LL	3.5mm +/-0.5mm
S	10mm +/-0.5mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	300
Weight:	10 g

General Information

Series:	SSHB10HS
Style:	Through-Hole
RoHS:	Yes
Notes:	Marking: 22 Lot No.
Miscellaneous:	Temperature Rise Maximum: 55 K

Specifications

Voltage AC:	250 VAC
Inductance:	1.1 mH (10 kHz)
Current:	2.2 A
Temperature Range:	-25/+130C
DC Resistance:	110 mOhms