

## PCRS\_LCAX\_LCAX\_A221T\_XX.X\_SS

### Description

Duplex patch cord, LC uniboot push-pull XD to LC uniboot push-pull XD,APC,duplex round 2.1mm\_XX.X\_yellow,SM G.657.A2



Features	Features
- High mechanical stability	
- Colour coded boot for good visibility also in mated condition	

### Technical Data

#### General Data

Description	Values
General Typ	Duplex LC patch cord
Operation temperature	-25 up to 70°C
Polarity	A-B / B-A straight polarity (standard)
UL Rating	UL 94 V-0
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes

#### Connector left

Description	Values
Connector typ	LC-XD duplex Uniboot
Polish	APC
Color Housing	Black
Color Clip	Green
Color Boot	Black
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	S
Insertion loss 97% dB / mean dB	0.45 / 0.2
Return Loss	>65dB
Durability	1000
Tensile load	70 N
Tensile load acc. To GR-326-COR	Fullfiled

#### Connector right


Description	Values
Connector typ	LC-XD duplex Uniboot
Polish	APC
Color Housing	Black
Color Clip	Green
Color Boot	Black
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	S
Insertion loss 97% dB / mean dB	0.45 / 0.2
Return Loss	>65dB
Durability	1000
Tensile load	70 N
Tensile load acc. To GR-326-COR	Fullfiled

## PCRS\_LCAX\_LCAX\_A221T\_XX.X\_SS

### Cable

Description	Values
Cable typ	Riser Cable
Fiber count	2
Fiber	2 x 0.6 mm
Fiber type	E9/125-SM G.657.A2
Outer diameter	2.1 mm
Outer jacket material	Jacket material according to UL 94V-0

### Technical Drawing

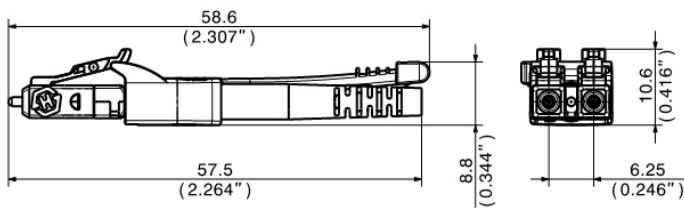

### Ordering information

Meter (m)	Item number	Description
1	85020987	PCRS_LCAX_LCAX_A221T_01.0_S
2	85020988	PCRS_LCAX_LCAX_A221T_02.0_S
3	85020989	PCRS_LCAX_LCAX_A221T_03.0_SS
5	85020991	PCRS_LCAX_LCAX_A221T_05.0_SS
6	85020992	PCRS_LCAX_LCAX_A221T_06.0_S
7	85020993	PCRS_LCAX_LCAX_A221T_07.0_S
10	85020994	PCRS_LCAX_LCAX_A221T_10.0_SS
15	85020995	PCRS_LCAX_LCAX_A221T_15.0_S
20	85020996	PCRS_LCAX_LCAX_A221T_20.0_S
3.5	85020990	PCRS_LCAX_LCAX_A221T_03.5_S