


**R0828 Rack Rail**

Full Hole Imperial Rack Rail, Tapped to 10/32 UNF. Black Powder Coated. Available Cut From 1 Space to 45 Spaces. Please Specify length (Number of Spaces) when Ordering. Use U5200 or U5205 Rack Screws and U5215 Washers. We recommend that you use a max Torque setting of 4kns when tightening the rack fastenings.

Material: 3.0mm / 1/8" Steel

Part Number	Available Sizes
<b>R0828</b>	1 Space (44.45mm / 1.75") to 45 Spaces (2m / 6ft 7")

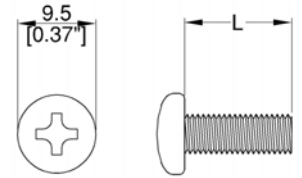


**U5200 - U5205**

10/32 UNF Rack Screws  
Mates with R0827- R0828  
Phillips Pan Head.  
Sold in Packs of 25pcs.

Material: Steel

Part Number	Length (L)	Weight
<b>U5200</b>	13mm / 1/2"	0.2Kg/0.44Lb Per 100
<b>U5205</b>	19mm / 3/4"	0.3Kg/0.66Lb Per 100

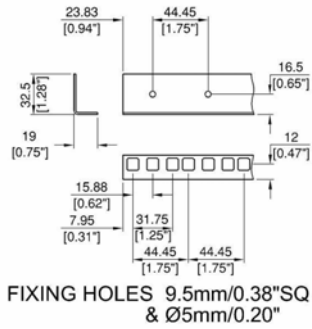



**R0863 Rack Strip**

Full Hole Rack Strip. Black Powder Coated. Available Cut From 1 Space to 45 Spaces. Please Specify length (Number of Spaces) when Ordering. Compatible with S1170/ S1172 Captive Nuts, S1045 M6 Screws and S1940 - S1941 Cup Washers. For Universal Rack Cage Nut Tool see part SX1100

FIXING HOLES 9.5mm/0.38"SQ & Ø5mm/0.20"

Material: Steel

Part No.	Finish	Thickness	Available Sizes	Weight
<b>R0863</b> <b>R0863/2mm</b>		1.5mm / 16 gauge 2.0mm / 14 gauge	1 Space (44.45mm / 1.75") to 45 Spaces (2m / 6ft 7")	0.895Kg/1.97Lb 1.397Kg/3.08Lb
<b>R0889Z-25</b> <b>R0889K-25</b>	Zinc Black	M6 Screw Pack, 25 Sets.		

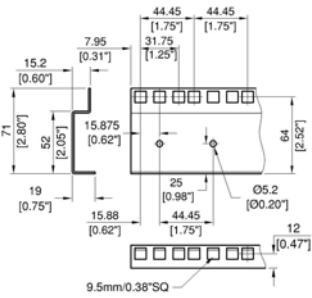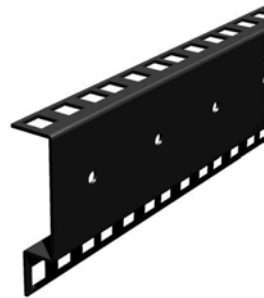

**R0883 Rack Strip**

Full Hole Double Rack Strip. Black Powder Coated. Available Cut From 1 Space to 45 Spaces. Please Specify length (Number of Spaces) when Ordering. Compatible with S1170/ S1172 Captive Nuts, S1045 M6 Screws and S1940 - S1941 Cup Washers. For Universal Rack Cage Nut Tool see part SX1100

Material: Steel

Part No.	Finish	Thickness	Available Sizes	Weight
<b>R0883</b> <b>R0883/2mm</b>		1.5mm / 16 gauge 2.0mm / 14 gauge	1 Space (44.45mm / 1.75") to 45 Spaces (2m / 6ft 7")	1.901Kg/4.19Lb 2.566Kg/5.66Lb
<b>R0889Z-25</b> <b>R0889K-25</b>	Zinc Black	M6 Screw Pack, 25 Sets.		