


PREMIUM SMART WI-FI OUTDOOR IP CAMERA




SKU Code: IPC1021
EAN Code: 7061255086358

SKU Code: IPC1022
EAN Code: 7061255978196


3 Simple steps to install and Go Live!

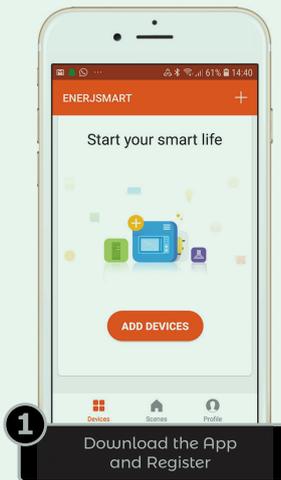

1 Download the App and Register

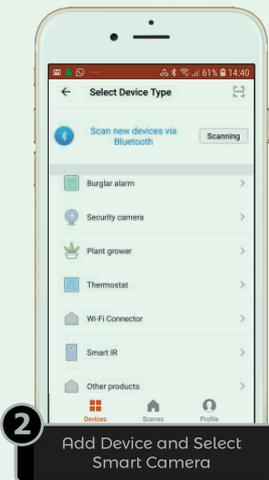

2 Add Device and Select Smart Camera

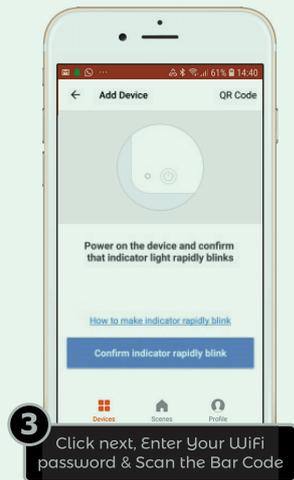

3 Click next, Enter Your Wifi password & Scan the Bar Code

Features

- Full 1080P HD Crystal Image: 2MP HD resolution and 30m IR Night Vision for crystal clear viewing day and night, IP65 Rating with Full Metal Casing makes the camera robust enough for outside use.
- TWO-WAY Audio & 110° Wide View Angle: Built-in Microphone and speaker allows you to communicate with guests and the deterrent alarm can scare off intruders out of your house. Equipped with a 3.9mm HD lens enables a larger field of view of 110°.
- Motion Detection & External SD slot design: Automatically record on Micro SD card (Up to 128G, No SD card pre-installed) When movement is detected. External SD card slot designing is easier for SD installation.
- Real-time push alarm: Free instant push alerts to your mobile/tablet when motion is detected. Playback recordings from mobile or PC whenever you want to check back on your home.

- Easy Installation and Remote viewing: Real Plug and Play and easy wifi set-up allows you to access the live feed in minutes, feel so close to your family with our wireless camera even you are not home.
- Works With Alexa Echo and Google Home: Not a normal ip camera, you could use amazon alexa to control our camera, simply link ENERJSMART app with your alexa app and just say alexa, turn on the camera. Then you could see image on your echo show. You can also add on more ENER-J products such as wifi sensors and group them with this IP Camera.



Specifications	
SKU	IPC1021 (1MP), IPC1022 (2MP)
Camera	
DSP	RTS3903
Image sensor	1/2.7-inch CMOS 2M pixels
Lens	4mm fixed
Minimum illumination	0.01Lux
Night vision range	8-10 meters
IR cut filter	IR cut filter with auto switch
Termination(s)	N/A
PIR Motion sensor	Yes
Video/Image	
Resolution	720P / 1MP, 1080P / 2MP
Compression	H.264 High profile
Effective number of pixels	1280*720P (1MP), 1920*1080P (2MP)
Viewing angle	85 degree
Frame rate	15 FPS
Mirror/Flip	Yes
View mode	HD & SD
Features	Privacy zone, Smart config, Movement tracking
Audio	
Communication	N/A
Input	Built in MIC
Output	Built in MIC
Audio	
Interface	NO RJ45
Supported protocols	IP, TCP, DHCP WPS.

Dynamic DNS	Yes
Port forwarding	P2P
Stream	Dual Stream
DHCP	Automatic
Wireless	
Standards	IEEE 802.11n: 150Mbps IEEE 802.11g: 54Mbps IEEE 802.11b: 11Mbps
Frequency	2.4GHz
Antennas	One, Omnidirectional
Antenna gain	3dBi
Network security	WEP, WPA, WPA2
Surveillance management	
Remote management	app remote
Multiple user management	N/A
Split screen view	N/A
Mobile app	iOS & Android
Alarm and notifications	
Motion detection	Yes
Notification method	Mobile push
Notification scheduling	1 Minute
Additional information	
Warranty and tech support	1 Year
Certifications	FCC ID, UL request
Smart APP	Enerjsmart
Cloud	Tuya Cloud base
Power	12V
Adapter	Included with UK plug
Cable	1.3m Cable Included

