

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

22-03-5035

Status:

Active

Overview:

SPOX™ Wire-to-Board Connectors

Description:

2.50mm Pitch SPOX™ Wire-to-Board Header, Vertical, Shrouded, 3 Circuits, Tin (Sn) Plating

Documents:

3D Model

Drawing (PDF)

Product Specification PS-5264-001 (PDF)

Packaging Specification SPK-5267-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

PCB Headers

Series

5267

Application

Signal, Wire-to-Board

MolexKits

Yes

Overview

SPOX™ Wire-to-Board Connectors

Product Name

SPOX™

UPC

800753625730

Physical

Breakaway

No

Circuits (Loaded)

3

Circuits (maximum)

3

Color - Resin

Natural

Durability (mating cycles max)

30

First Mate / Last Break

No

Flammability

94V-0

Glow-Wire Compliant

No

Guide to Mating Part

No

Keying to Mating Part

None

Lock to Mating Part

Yes

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Nylon

Net Weight

293.200/mg

Number of Rows

1

Orientation

Vertical

PC Tail Length

3.50mm

PCB Locator

No

PCB Retention

Yes

PCB Thickness - Recommended

1.60mm

Packaging Type

Bag

Pitch - Mating Interface

2.50mm

Plating min - Mating

4.064µm

Plating min - Termination

4.064µm

Polarized to Mating Part

Yes

Polarized to PCB

No

Shrouded

Fully

Stackable


No

Surface Mount Compatible (SMC)

No

Temperature Range - Operating

-40°C to +105°C

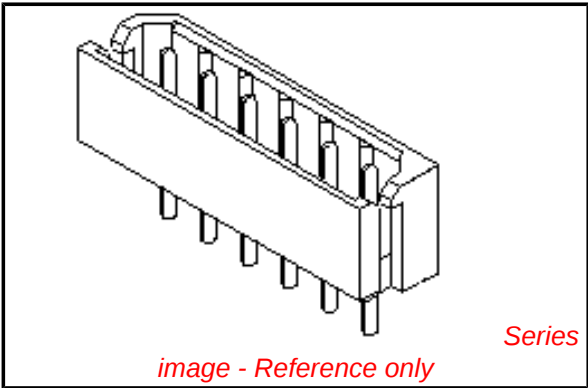

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
5267Series

Mates With
5264 SPOX™ Wire-to-Board Crimp Housing, [42219](#) SPOX™ IDT Receptacle Housing

Termination Interface: Style	Through Hole
Electrical	
Current - Maximum per Contact	3A
Voltage - Maximum	250V
Material Info	
Old Part Number	5267-03A
Reference - Drawing Numbers	
Packaging Specification	SPK-5267-001
Product Specification	PS-5264-001, RPS-5264-005, RPS-5267-001
Sales Drawing	SD-5267-NA

This document was generated on 01/15/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION