

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

22-05-7055

Status:


Active

Overview:

SPOX™ Wire-to-Board Connectors

Description:

2.50mm Pitch SPOX™ Wire-to-Board Header, Right Angle, Shrouded, Friction Lock, 5 Circuits

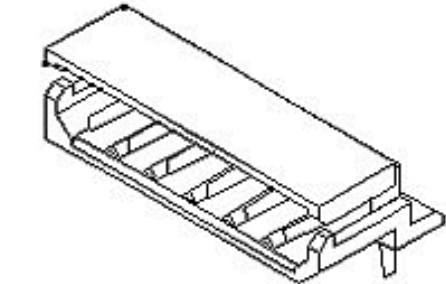

Series

image - Reference only

Documents:

3D Model

Drawing (PDF)

Product Specification PS-5264-001 (PDF)

Packaging Specification SPK-5268-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		LR19980
UL		E29179
General		
Product Family		PCB Headers
Series		5268
Application		Signal, Wire-to-Board
MolexKits		Yes
Overview		SPOX™ Wire-to-Board Connectors
Product Name		SPOX™
UPC		800753592797
Physical		
Breakaway		No
Circuits (Loaded)		5
Circuits (maximum)		5
Color - Resin		Natural
Durability (mating cycles max)		30
First Mate / Last Break		No
Flammability		94V-0
Glow-Wire Compliant		No
Guide to Mating Part		No
Keying to Mating Part		None
Lock to Mating Part		Yes
Material - Plating Mating		Tin
Material - Plating Termination		Tin
Material - Resin		Nylon
Net Weight		528.800/mg
Number of Rows		1
Orientation		Right Angle
PC Tail Length		3.50mm
PCB Locator		No
PCB Retention		None
PCB Thickness - Recommended		1.60mm
Packaging Type		Bag
Pitch - Mating Interface		2.50mm
Plating min - Mating		4.064µm
Plating min - Termination		4.064µm
Polarized to Mating Part		Yes
Polarized to PCB		No
Shrouded		Fully
Stackable		No
Surface Mount Compatible (SMC)		No
Temperature Range - Operating		-40°C to +105°C

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

5268Series

Mates With

5264 SPOX™ Wire-to-Board Crimp Housing

Termination Interface: Style	Through Hole
Electrical	
Current - Maximum per Contact	3A
Voltage - Maximum	250V
Material Info	
Old Part Number	5268-05A
Reference - Drawing Numbers	
Packaging Specification	SPK-5268-001
Product Specification	PS-5264-001, RPS-5264-005, RPS-5268-001
Sales Drawing	SD-5268-NA

This document was generated on 10/10/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION