

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0008701040

Status:


Active

Overview:

Mini-SPOX Wire-to-Board Connector System

Description:

2.50mm Pitch Mini-SPOX Crimp Terminal, 22-28 AWG, Bag

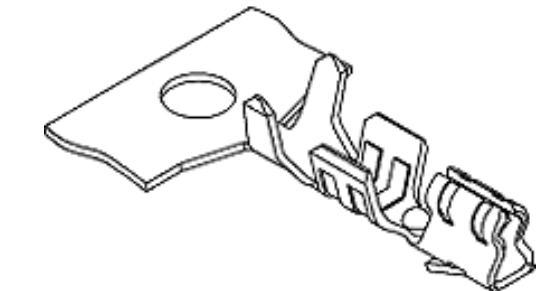

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-5264-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	5263
Application	Signal
Crimp Quality Equipment	Yes
Overview	Mini-SPOX Wire-to-Board Connector System
Packaging Alternative	08-70-1039 (Reel)
Product Name	Mini-SPOX
UPC	800753534919
Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	43.200/mg
Packaging Type	Bag
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.90mm max.
Wire Size AWG	22, 24, 26, 28
Wire Size mm²	N/A
Material Info	
Engineering Number	5263PBTL
Reference - Drawing Numbers	
Product Specification	PS-5264-001-001
Sales Drawing	SD-5263-003

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Prop65

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

5263 Series

Use With

5264 Mini-SPOX Crimp Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION