

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0022566107](#)  
**Status:** **Active**  
**Overview:** [SL Modular Connectors](#)  
**Description:** 2.54mm Pitch SL Crimp Housing, Dual Row, Version F, 10 Circuits, Black

**Documents:**

[3D Model](#) [Product Specification TS-70541-001-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Crimp Housings  
 Series [70450](#)  
 Application Signal, Wire-to-Board  
 Comments Version F, Version F  
 Overview [SL Modular Connectors](#)  
 Product Name SL  
 UPC 800754397926

**Physical**

Breakaway No  
 Circuits (maximum) 10  
 Color - Resin Black  
 Flammability 94V-0  
 Gender Receptacle  
 Glow-Wire Capable No  
 Material - Resin Polyester  
 Net Weight 0.960/g  
 Number of Rows 2  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 2.54mm  
 Stackable No  
 Temperature Range - Operating -40° to +105°C

**Solder Process Data**


Lead-freeProcess Capability N/A

**Material Info**

Engineering Number 704500253

**Reference - Drawing Numbers**

Product Specification TS-70541-001-001  
 Sales Drawing SD-70450-0250-0275

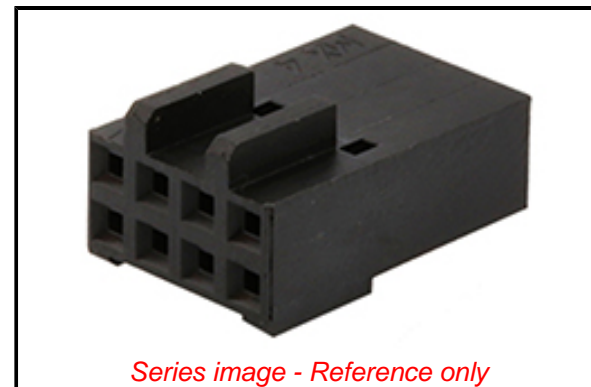

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/88/2018 (15  
 January 2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[70450](#) Series

**Mates With**

2.54mm Pitch C-Grid Header [70229](#) , [70280](#)  
 , [70246](#) , [70247](#)

**Use With**

[70058](#) , [71851](#)