

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0423751246](#)
Status: **Active**
Description: KK 100 Hdr Assy Bkwy 04 Ckt Tin

Documents:

Drawing (PDF)	Packaging Specification PK-40873-0041-001 (PDF)
Product Specification PS-10-07-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	PCB Headers
Series	42375
Application Tooling Part Link	11-20-1230
Product Name	KK 254
UPC	800753812260

Physical

Flammability	94V-0
Net Weight	0.244/g

Electrical

Voltage - Maximum	500V
-------------------	------


Solder Process Data

Duration at Max. Process Temperature (seconds)	005
Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	235

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-40873-0041-001
Product Specification	PS-10-07-001
Sales Drawing	SD-42375-001

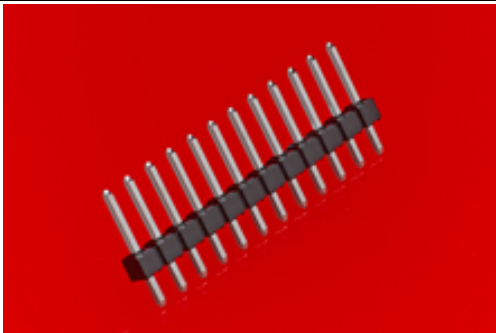

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[42375](#) Series