

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0878980304**
Status: **Active**
Overview: C-Grid Connector Products
Description: C-Grid / SL Header, Surface Mount, Breakaway, Vertical, 3 Circuits, 0.38µm Gold (Au) Plating, Tray Packaging, without Cap, Lead-Free

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-89990-489-001 \(PDF\)](#)
[Product Specification PS-87920-019-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family PCB Headers
 Series [87898](#)
 Application Board-to-Board, Signal, Wire-to-Board
 Overview [C-Grid Connector Products](#)
 Product Name C-Grid, SL
 UPC 822350015585

Physical


Breakaway Yes
 Circuits (Loaded) 3
 Circuits (maximum) 3
 Color - Resin Black
 First Mate / Last Break No
 Flammability 94V-0
 Glow-Wire Capable No
 Guide to Mating Part No
 Keying to Mating Part None
 Lock to Mating Part None
 Material - Metal Copper Alloy
 Material - Plating Mating Gold
 Material - Plating Termination Tin
 Material - Resin Nylon
 Net Weight 0.165/g
 Number of Rows 1
 Orientation Vertical
 PCB Locator No
 PCB Retention None
 Packaging Type Tray
 Pitch - Mating Interface 2.54mm
 Pitch - Termination Interface 2.54mm
 Polarized to Mating Part No
 Polarized to PCB No
 Shrouded No
 Stackable No
 Temperature Range - Operating -55° to +105°C
 Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 3.0A
 Voltage - Maximum 250V

Solder Process Data

Duration at Max. Process Temperature (seconds) 010

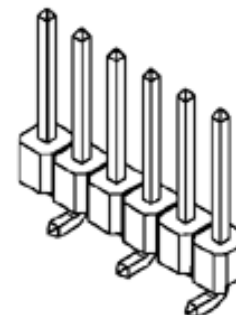

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/88/2018 (15
 January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[87898](#) Series

Mates With

[4455](#) KK PCB Receptacles, [70430](#) SL IDT Housings, [7720](#) KK IDT Housings, [70400](#) KK IDT Housings, [90147](#) , [90148](#) C-Grid PCB Receptacles

Lead-free Process Capability	REFLOW
Max. Cycles at Max. Process Temperature	003
Process Temperature max. C	260

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-89990-489-001
Product Specification	PS-87920-019-001
Sales Drawing	SD-87898-001-000, SD-87898-003-001

This document was generated on 03/18/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION