

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190330003**
Status: **Active**
Overview: Snap Plugs and Receptacles
Description: Krimptite Snap Plug, for 18-22 AWG Wire

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E152602

General

Product Family Quick Disconnects
 Series 19033
 Crimp Quality Equipment Yes
 Insulated No
 Overview Snap Plugs and Receptacles
 Product Name Krimptite
 Type Snap Plug
 UPC 800755058970

Physical

Barrel Type Closed
 Gender Male
 Glow-Wire Capable No
 Insulation None
 Lock to Mating Part None
 Material - Metal Brass
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 0.962/g
 Orientation Straight
 Packaging Type Bag
 Plating min - Mating 2.540µm
 Plating min - Termination 2.540µm
 Tab Thickness N/A
 Tab Width N/A
 Termination Interface: Style Screw or Lug
 Wire Insulation Diameter N/A
 Wire Size AWG 18, 20, 22

Electrical


Voltage - Maximum N/A

Material Info

Engineering Number A-169

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing SD-19033-001

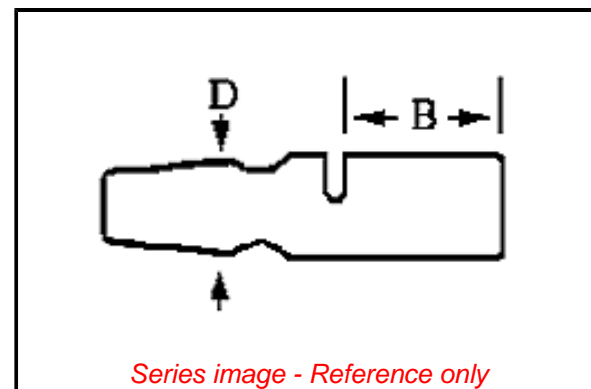

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/88/2018 (15
 January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19033 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand Crimp Tool	<u>640030100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640070100</u>