


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0672984091](#)  
**Status:** **Active**  
**Overview:** [USB Products and Solutions](#)  
**Description:** Universal Serial Bus (USB) Shielded I/O Receptacle, Right-Angle, Dual Stacked, Type A, 0.76µm Gold (Au) Plating, White Housing, with 4 Beveled Metal Pins, Lead-Free

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification TS-67298-008-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification PK-67298-003-001 (PDF)</a>
<a href="#">Product Specification PS-67298-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

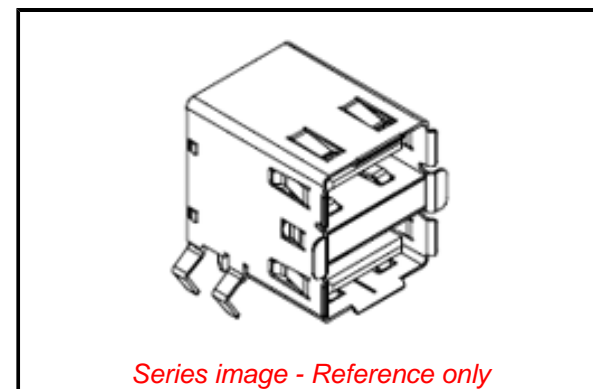

**General**

Product Family	I/O Connectors
Series	<a href="#">67298</a>
Application	Wire-to-Board
Comments	4 Beveled Metal Pins, 4 Beveled Metal Pins
Component Type	Receptacle
Overview	<a href="#">USB Products and Solutions</a>
Product Name	USB 2.0
Type	A
UPC	822350050920

**Physical**

Boot Color	N/A
Circuits (Loaded)	8
Circuits (maximum)	8
Gender	Female
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	4.890/g
Number of Rows	2
Orientation	Right Angle
PC Tail Length	2.80mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Tray
Panel Mount	Yes
Pitch - Mating Interface	2.00mm, 2.50mm
Pitch - Termination Interface	2.00mm, 2.50mm
Plating min - Mating	0.762µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	2
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	0° to +50°C
Termination Interface: Style	Through Hole
Waterproof / Dustproof	No

**Electrical**

Current - Maximum per Contact	1.5A
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	30V DC

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[67298 Series](#)

**Mates With**

USB Type A Plug

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification

Product Specification

Sales Drawing

PK-67298-003-001

PS-67298-001-001, TS-67298-008-001

SD-67298-008-001

This document was generated on 03/18/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**