


Datasheet

EV5-209A IRS 2-Way Active Tap (124259)

The EV5-209A IRS 2-Way Active Tap is designed to be used in the trunk lines when the signal requires re-amplification and eliminates the need to have a repeater amplifier. Ideal for distributing signals to the floor below from output 2.

- IRS 2-Way Active Tap
- Output 1 10dB Sat, 6dB Terr Right Output
- Output 2 0dB Sat, 0dB Terr Left Output
- Colour coded inputs / outputs
- Insertion Loss Sat <2dB, Terr <2dB
- Through Current 1 Amp per leg
- Fully screened die-cast housing to reject interference
- Factory fitted earth bars
- Enables easy distribution and balance of signals

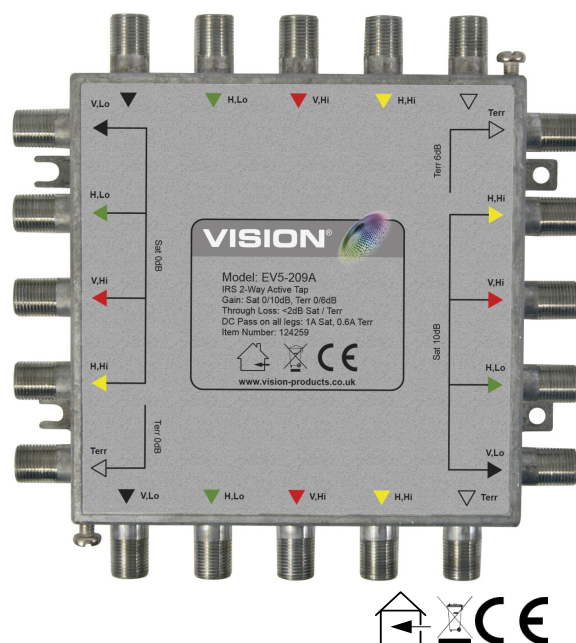

Model	EV5-209A (124259)
Frequency Range SAT	950MHz – 2200MHz
TERR	50 – 862MHz
Number of Inputs / Tapped Outputs / Outputs	5/2*5/5
Sat / Terr Gain Output 1	10dB / 6dB
Sat / Terr Gain Output 2	0dB / 0dB
Maximum Input IMD ⁻³⁵ Sat / Terr	100dBμV (88dBμV de-rated) / 100dBμV (94dBμV de-rated)
Insertion Loss SAT / Terr	<-2dB / <-2dB
SAT IF / SAT IF Input Isolation	>25dB
SAT IF / Terr Input Isolation	>25dB
SAT IF Output – SAT Output Isolation	>25dB
Terr / Terr- Output Isolation	>25dB
Return Loss All ports	>10dB
DC Consumption Terr TV amplifier via H lines	12-18VDC 70mA
Impedance	75Ω
Connectors	F-Type (f) Earth Bar F-Type (f) Quick F (m)
Max DC Pass into the trunk	18V 1.0A per leg
Operating Temperature	-20°C to +50°C
Dimension inc connectors (mm) / Weight	134 x 134x 30mm 472g

In the interests of continued product improvement and development we reserve the right to change specifications, design and dimensions without prior notice.
Details correct at date of publication E&OE ©2018 Vision Products (Europe) Ltd

Vision Products (Europe) Ltd, Redbourne Park, Liliput Road, Brackmills, Northampton NN4 7DT
Tel: 01604 662748 Fax: 01604 662746 Email: technical@vision-products.co.uk
Company Reg No: 5044512
www.vision-products.co.uk