

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0008550129**  
**Status:** **Active**  
**Overview:** KK® Interconnect System - Molex  
**Description:** KK High Pressure Crimp Terminal 7879, 22-30 AWG, Bag Selective Gold (Au)

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-2759-002-001 \(PDF\)](#)  
[Product Specification PS-7879-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Packaging Specification PK-2759-001 \(PDF\)](#)

**General**

Product Family Crimp Terminals  
Series 7879  
Application Signal  
Crimp Quality Equipment Yes  
Overview KK® Interconnect System - Molex  
Packaging Alternative 08550124 (Reel)  
Product Name KK High Pressure  
UPC 800754226523

**Physical**

Gender Female  
Material - Metal Brass  
Material - Plating Mating Gold  
Material - Plating Termination Tin  
Net Weight 0.117/g  
Packaging Type Bag  
Plating min - Mating 0.381µm  
Plating min - Termination 2.540µm  
Termination Interface: Style Crimp or Compression  
Wire Insulation Diameter 1.57mm max.  
Wire Size AWG 22, 24, 26, 28, 30  
Wire Size mm² N/A

**Solder Process Data**


Lead-freeProcess Capability N/A

**Material Info**

Engineering Number 7879-1(P208)L

**Reference - Drawing Numbers**

Packaging Specification PK-2759-001, PK-2759-002-001  
Product Specification PS-7879-001  
Sales Drawing SD-7879

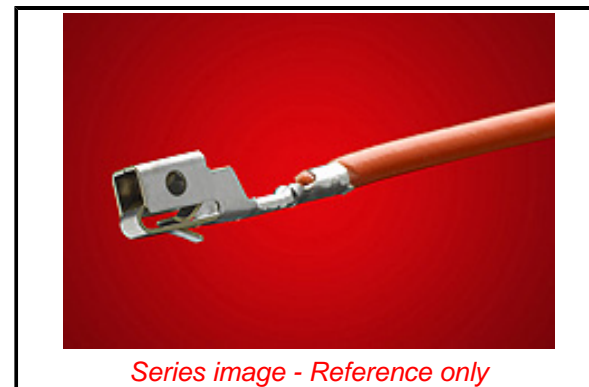

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

7879 Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
Extraction Tool	<u>11030022</u>
Insertion Tool	<u>638120000</u>
Hand Crimp Tool	<u>638190800</u>