


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0528851074](#)
Status: **Active**
Overview: SlimStack™ 0.635mm Pitch Board-to-Board Connectors
Description: SlimStack Board-to-Board Connector, 0.635mm Pitch, 0.635 Series, Receptacle, 6.00 to 10.00mm Mated Height, 6.40mm Mated Width, 100 Circuits

Documents:

3D Model	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	Product Literature (PDF)
Product Specification 527600000-000 (PDF)	Product Literature (PDF)
Packaging Specification SPK-52885-001-001 (PDF)	

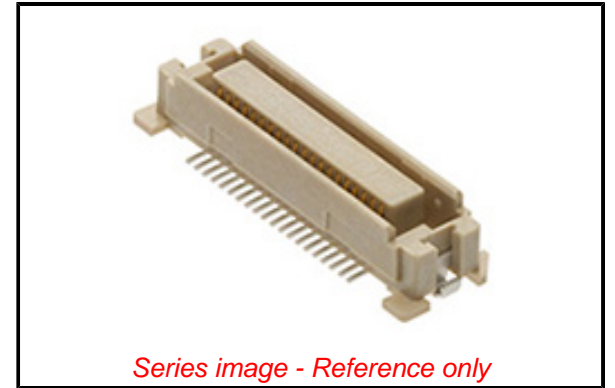

Agency Certification

UL E29179

General

Product Family	PCB Receptacles
Series	52885
Application	Board-to-Board, Signal
Comments	Stacking-Type, Stacking-Type
Datasheet Order No	987651-8807, 987651-8808_ZH, 987651-8810_DE, 987651-8811_JA, 987651-8812_KO, 987651-8813_ES
Overview	SlimStack™ 0.635mm Pitch Board-to-Board Connectors
Product Guide Order No	987651-8281
Product Literature Order No	987652-0196, Reference Guide#
Product Name	SlimStack
Series Name	0.635
UPC	822348166060

Physical

Circuits (Loaded)	100
Circuits (maximum)	100
Color - Resin	Natural
Durability (mating cycles max)	50
Flammability	94V-0
Glow-Wire Capable	No
Lock to Mating Part	None
Mated Height	10.00mm, 6.00mm, 7.00mm, 8.00mm, 9.00mm
Mated Width	6.40mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1221.601/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.64mm
Plating min - Mating	0.254µm
Plating min - Termination	2.032µm
Polarized to PCB	Yes
Robotic Placement	Pick and Place Cap
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-55° to +105°C

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[52885 Series](#)

Mates With

[55091](#) , [53649](#) , [53627](#) , [53647](#) , [53625](#)

Termination Interface: Style

Surface Mount

Electrical

Current - Maximum per Contact

0.5A

Voltage - Maximum

100V

Material Info

Reference - Drawing Numbers

Packaging Specification

SPK-52885-001-001

Product Specification

527600000-000

Sales Drawing

SD-52885-003-001, SD-52885-004-001

This document was generated on 04/02/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION