


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0471511061](#)  
**Status:** **Active**  
**Overview:** High Definition Multimedia Interface (HDMI)\* Products  
**Description:** 0.50mm Pitch HDMI Receptacle, Right-Angle, Front Solder Tab Length 1.80mm, Contact 0.76µm Gold (Au) Plated, with Back Cover and Mylar, without Upper Flange, Tape and Reel Package, Black Housing, Lead-Free

**Documents:**

[3D Model](#) [Packaging Specification PK-47151-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-47152-001 \(PDF\)](#)

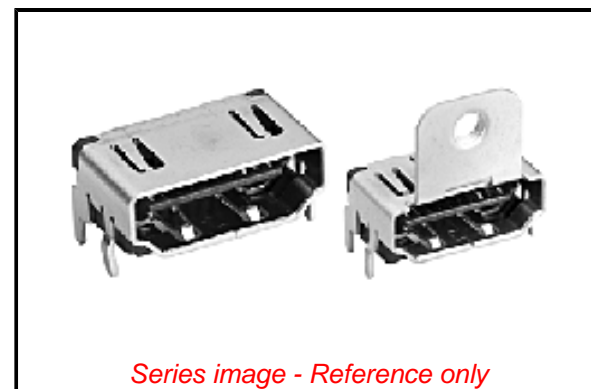

**General**

Product Family	I/O Connectors
Series	<a href="#">47151</a>
Application	Wire-to-Board
Component Type	Receptacle
Electrical Model	Yes
Overview	<a href="#">High Definition Multimedia Interface (HDMI)* Products</a>
Product Name	HDMI
Type	N/A
UPC	822350941365

**Physical**

Boot Color	N/A
Circuits (Loaded)	19
Color - Resin	Black
Flammability	94V-0
Gender	Female
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin-Bismuth
Net Weight	2.197/g
Number of Rows	2
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Panel Mount	Without Flange
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	0.762µm
Plating min - Termination	1.016µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Temperature Range - Operating	-20° to +85°C
Termination Interface: Style	Surface Mount
Waterproof / Dustproof	No
Wire Size AWG	N/A

**Electrical**

Current - Maximum per Contact	0.5A
Shielded	Yes
Voltage - Maximum	40V DC

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Contained Per -  
ED/61/2018 (27 June  
2018)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[47151](#) Series

**Mates With**

[88768](#) HDMI Cable Assembly, [88764](#) HDMI Adapter, [88767](#) HDMI Adapter

**Solder Process Data**

Duration at Max. Process Temperature (seconds)	002
Lead-free Process Capability	REFLOW
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	245

**Material Info****Reference - Drawing Numbers**

Electrical Model Document	EE-47151-001, EE-47151-002
Packaging Specification	PK-47151-001
Product Specification	PS-47152-001
S-Parameter Model	SP-47151-002

This document was generated on 04/02/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**