

## XZCPY4275L10

pre-wired connectors XZ - straight female - 7/8" - 4 pins - cable PVC 10m



### Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	General purpose

### Complementary

Electrical connection	7/8", 4 pins straight female connector
Cable connector fixing	Screw-on
Collar material	Metal
Status LED	Without
Cable length	10 m
Cable outer diameter	10.8 mm
Cable composition	4 x 1.5 mm <sup>2</sup>
Wire insulation material	PVC
[Ue] rated operational voltage	600 V DC 600 V AC
[In] rated current	10 A
Contact resistance	5000 µOhm
Insulating resistance	1 GΩ
Product weight	1.7 kg

### Environment

IP degree of protection	IP67
product certifications	CULus
ambient air temperature for operation	-25...80 °C (static)
ambient air temperature for storage	-25...80 °C


### Offer Sustainability

Sustainable offer status	Not Green Premium product
RoHS (date code: YYWW)	Compliant - since 1201 - Schneider Electric declaration of conformity

### Contractual warranty

Warranty period	18 months
-----------------	-----------


### Dimensions

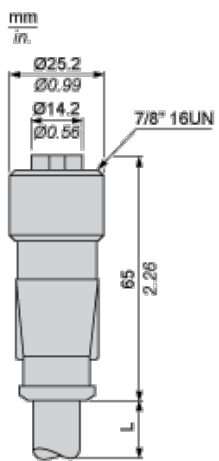

L : Length of cable

## Connections and Schemes
 
### Connectors



RD : Red

WH : White

BK : Black

GN : Green