

XZCRV2605V2X2

jumper cable XZ - male straight M8 4 pin - female straight M8 3 pin - PVC 2m



Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Jumper cable


Complementary

Jumper cable end 1	M8 male, :4 pins (straight), fixing: screw-on
Jumper cable end 2	M8 female, :3 pins (straight), fixing: screw-on
Collar material	Metal
Cable composition	3 x 0.25 mm ²
Cable length	2 m
Wire insulation material	PVC
Cable outer diameter	4.6 mm
[Ue] rated operational voltage	250 V AC 300 V DC
[In] rated current	3 A
Insulation resistance	>= 1000 MOhm
Resistance across terminals	<= 5000 mOhm
Product weight	0.09 kg

Environment

IP degree of protection	IP65 IP67
product certifications	CULus
ambient air temperature for operation	-25...80 °C (static)
ambient air temperature for storage	-25...80 °C

Dimensions

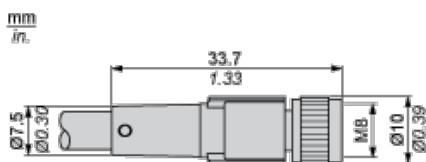

Connections and Schemes

