


▶ Manual Reset Thermostats

Type 05N / 05EP

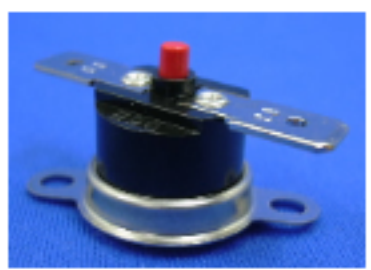

Type 05N / 05EP

1/2" Bimetallic Disc Thermostat

Manual Reset

05N: 125VAC / 15A, 250VAC / 10A
05EP: 125VAC / 0.1A, 30VDC / 0.1A

Standard: UL-E43273, CSA-LR67166

Item	Specifications
Basic Features	Manual Reset, SPST Bimetallic Disc Thermostat
Operation	A: Contacts open on temperature rise
Electrical Rate	Resistive: 125 VAC / 15A, 250VAC / 10A
Temperature Rating	Max Operating Temp 150°C (302°F)
Calibration Method	Hot Oven circulating System
Insulation Resistance	No less than 1,000 M(Omega) at DC 500V with Megger
Dielectric Strength	AC 1,500 Vfor 1 minute or AC 1,800 V for 1 second

Structure	Dimensions