

**SlimFix
SFX 11/60 MM GE**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

**Highly flexible: SFX**

SFX markers are the preferred choice for labelling cables if you prefer the classic cable tie solution. Cables do not always run in a straight line. The material used in SFX markers addresses this fact with highly flexible polyurethane. The marker follows each curve of the cable and latches on with ease.

General ordering data

| | |
|--------------------|--|
| Type | SFX 11/60 MM GE |
| Order No. | 2005400000 |
| Version | SlimFix, Conductor and cable markers, 7 - , 60 x 13 mm, yellow |
| GTIN (EAN) | 4050118390209 |
| Qty. | 1,000 pc(s). |
| compatible printer | 2430920000 2448870000 |

Data sheet

SlimFix SFX 11/60 MM GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|---------|-----------------|------------|
| Width | 13 mm | Width (inches) | 0.512 inch |
| Height | 60 mm | Height (inches) | 2.362 inch |
| Depth | 0.6 mm | Depth (inches) | 0.024 inch |
| Net weight | 0.566 g | | |

General data

| | | | |
|-----------------------------|--------------|-------------------------|--------------|
| Colour | yellow | Halogen | No |
| Material | Polyurethane | Number per roll | 1,000 |
| Operating temperature range | -40...90 °C | Size of labelling field | 44 x 10.5 mm |
| UL 94 flammability rating | HB | Version | halogen-free |
| Width | 13 mm | | |

Conductor and cable markers

| | | | |
|----------------|-----|----------------------|------|
| Conductor O.D. | 7 - | Conductor O.D., min. | 7 mm |
| Halogen | No | | |

Classifications

| | | | |
|------------|-------------|------------|-------------|
| ETIM 5.0 | EC001530 | ETIM 6.0 | EC001530 |
| eClass 6.2 | 27-40-04-01 | eClass 9.0 | 27-40-04-01 |
| eClass 9.1 | 27-40-04-01 | | |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads


| | |
|------------------|--|
| Engineering Data | EPLAN, WSCAD, Zuken E3.S |
| Engineering Data | STEP |

Data sheet

SlimFix
SFX 11/60 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

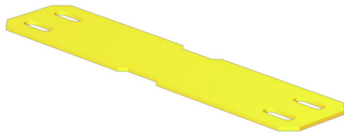

**SlimFix
SFX 11/60 MM GE**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

Ink ribbons THM MMP



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| Type | Order No. | Version | GTIN (EAN) | Qty. |
|------------------------|----------------------------|------------|---------------|----------|
| RIBBON MM 76/360 SW | 2005080000 | Ink ribbon | 4050118389951 | 1 pc(s). |

Accessories / replacement parts



Our marking systems can be used to quickly and reliably label connector markers, conductor and cable markers, device markers and labels. The M-Print® PRO software enables rapid and easy identification of your electrical equipment. You can design, label and order your marking materials professionally and quickly. Frames, barcodes, graphics or photos are easily incorporated. The versatile data conversion routines enable quick and flexible data integration. The Weidmüller PrintJet ADVANCED, MCP Plus and MCP Basic printers and the THM series printers are available for printing.

General ordering data

| Type | Order No. | Version | GTIN (EAN) | Qty. |
|-----------------------|----------------------------|---------|---------------|----------|
| THM MMP ROLLER 115 | 1357420000 | | 4050118160314 | 1 pc(s). |