

WP 120

Product no.: T0052919399N



Benefits

- › Soldering Iron 120 W, 24 V
- › For small and large components (High Mass) with high energy demand
- › Allrounder for WT stations and WR rework stations
- › Interchangeable XT soldering tips at low cost prices
- › Power Response heating technology with improved sensor position
- › Fast reaction time


For this purpose, we recommend:



Solder fume extractors



Pre-heating plates

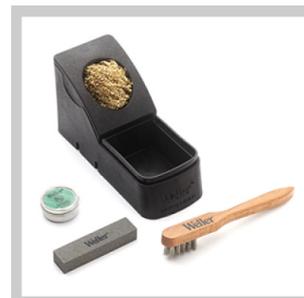

Cleaning




Soldering tips



Technical Data

Active Tip heating element technology	---
Power Response heating element technology	on
Silver Line heating element technology	---
Voltage	24 V
Power	120 W
Tip range	XT, XT Soldering head
Supply unit	PUD 121, PU WAD 101IG, WD 1M, WR 2, WR 3M, WR 3ME
WX-compatible	---
Temperature range °C	50 - 450
Temperature range °F	150 - 850
Heating time	14
Safety rest	---
Safety rest (optional)	WDH 10 (T0051512199), WDH 10T (T0051516199)
Barrel	T0058763709, T0058765802
Integrated direct extraction	---

Owning the bench

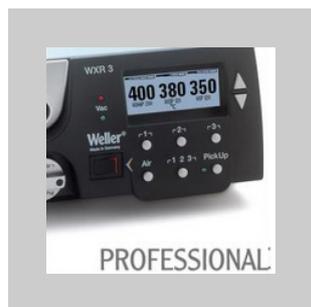

PROFESSIONAL



FILTRATION



EREM



XCELITE