

# WP 65 Set

Product no.: T0052921699N



## Benefits

- › Soldering Iron 65 W, 24 V
- › For small and medium components with average energy demand
- › For fine solder jobs with WT stations and WR rework stations
- › Interchangeable XNT soldering tips at low cost prices
- › Power Response heating technology with improved sensor position
- › fast reaction time


For this purpose, we recommend:




Solder fume extractors



Pre-heating plates

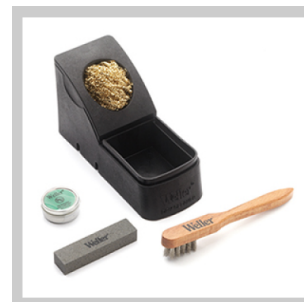

Cleaning

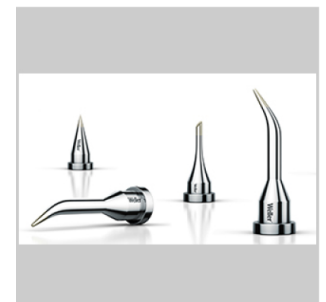

Soldering tips



### Technical Data

Active Tip heating element technology	---
Power Response heating element technology	on
Silver Line heating element technology	---
Voltage	24 V
Power	65 W
Tip range	XNT
Supply unit	PU 81, PUD 81, PUD 81i, PUD 121, PUD 151, WD 1M, WR 2, WR 3M, WR 3ME
WX-compatible	---
Temperature range °C	50 - 450
Temperature range °F	150 - 850
Heating time	7
Safety rest	WDH 10 (T0051512199)
Safety rest (optional)	WDH 10 (T0051512199), WDH 10T (T0051516199)
Barrel	T0058765758, T0058765767
Integrated direct extraction	---

### Owning the bench



PROFESSIONAL

PROFESSIONAL



FILTRATION

FILTRATION



EREM

EREM



XCELITE

XCELITE