

PU 81 CONTROL UNIT 230V UK

Power unit, 80 W, 230 V, analogue
Product no.: T0053252399N




Benefits

- Power unit 80 W


For this purpose, we recommend:



Solder fume extractors

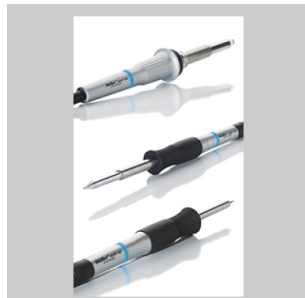

Soldering irons

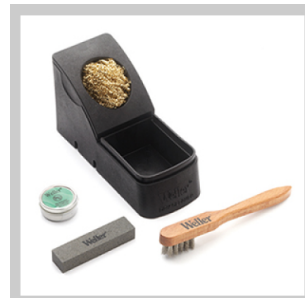

Cleaning




Pre-heating plates



Technical Data

Dimensions L x W x H (mm)	170 x 118 x 102 mm
Dimensions L x W x H (inches)	6,69 x 4,65 x 4,02 Inch
Weight (approx.) in kg	1,89 kg
Voltage	230 V
Power	95 W
Channels	1
Temperature range (depends on tool) °C	150 - 450
Temperature range (depends on tool) °F	302 - 842
Temperature accuracy °C	±9
Temperature accuracy °F	± 17
Temperature stability °C	tbd
Temperature stability °F	tbd
Equipotential bonding socket	Via a 3.5 mm jack bush (initial state-hard-grounded)
Display	---
Air consumption l/min	---
Operating pressure in bar/psi	---
Capacity l/min	---
Vacuum	---

Owning the bench

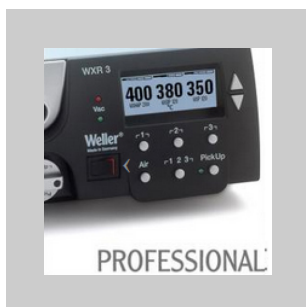

PROFESSIONAL



FILTRATION



EREM



XCELITE