

# WR 2000ER SET DSX120/WP65 230V UK F/G

2-Channel Rework Station, 200 W (300 W)  
Product no.: T0053380870N



## Benefits

- › Power unit, 2 channels with desoldering iron DSX 120, soldering iron WP 65 and safety rests WDH 10 and WDH 30
- › Repair kit for soldering and desoldering



For this purpose, we recommend:



Solder fume extractors



Soldering irons



Cleaning




Pre-heating plates



**Technical Data**

Dimensions L x W x H (mm)	273 x 235 x 102
Dimensions L x W x H (inches)	10,75 x 9,2 x 4,02
Weight (approx.) in kg	6.7
Voltage	---
Power	250 W (300 W)
Channels	2
Temperature range (depends on tool) °C	50 - 550
Temperature range (depends on tool) °F	150 - 950
Temperature accuracy °C	±9
Temperature accuracy °F	±17
Temperature stability °C	±2
Temperature stability °F	±4
Equipotential bonding socket	Via a 3.5 mm jack bush (initial state-hard-grounded)
Display	---
Air consumption l/min	---
Operating pressure in bar/psi	---
Capacity l/min	---
Vacuum	---

Owning the bench

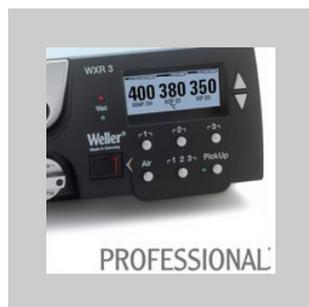

PROFESSIONAL



FILTRATION



EREM



XCELITE