




# 952.534UK

## 2 WAY CEILING SPEAKER

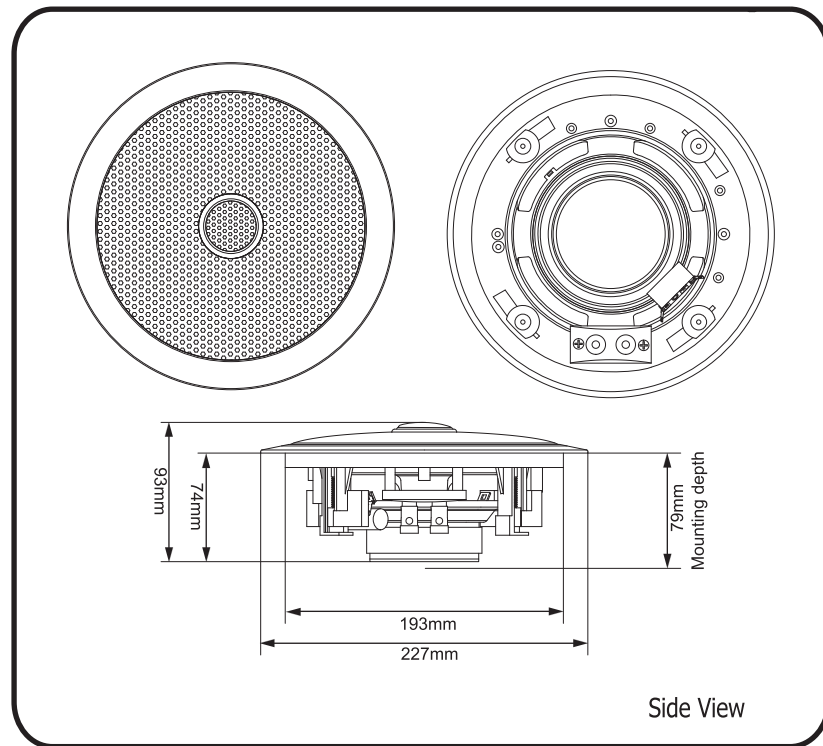

[www.avsl-adastra.com](http://www.avsl-adastra.com)

### 952.534UK

### Technical Specifications

Rated power	50 Watts RMS
Driver impedance	8 Ohms
Effective frequency range (BS6840)	60-20 KHz
S.P.L@1m, 1watt, dB, Test Signal Bandwidth 100Hz - 10KHz	86 Hz
S.P.L@ Full power Octave Bandwidth	85 dB ± 2 dB
Acoustic Power (dB, PWL@1 watt) 1k/2kHz	83/83 dB
Overall diameter	Φ 227mm
Net weight	1 Kgs
Colour/Finish	White
Material	Plastic Baffle ABS with UV inhibitors Metal Driver Chassis & Grille
Mounting Depth	79mm
Cut-out	Φ 193mm

