




MiHomeTM
 is a smart home

Dimmer (6mm)
 Take control of your lighting
 from anywhere




Product Description

The MiHome Dimmer switches are control only products. Each switch is individually controllable and you are able to use all the control features in the MiHome App including simple on/off, timers and geofencing on each switch individually. Dimmer switches are also controllable via the MiHome remote control. All MiHome light switches come in 5 finishes.

Technical Information

- Model: MIHO010, MIHO084, MIHO085, MIHO086, MIHO087
- Radio frequency: 433.92MHz
- Transmission range: 30m (in open area)
- Rating: 220-240V 50Hz, 1A, 250W
- Terminal connections: L, LI, SLAVE
- Energenie recommends using dimmable LED bulbs

MiHome lets you take control of your heating, lighting and appliances from anywhere

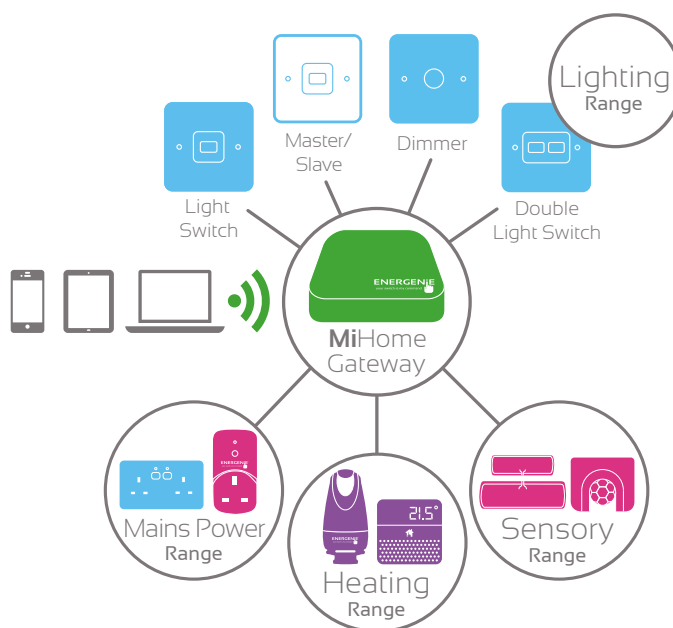

ENERGENIE[®]
 your switch is my command 

0844 412 7923
energenie4u.co.uk

