




MiHome™  
is a smart home

## Master Switch & Slave

Take control of your lighting  
from anywhere

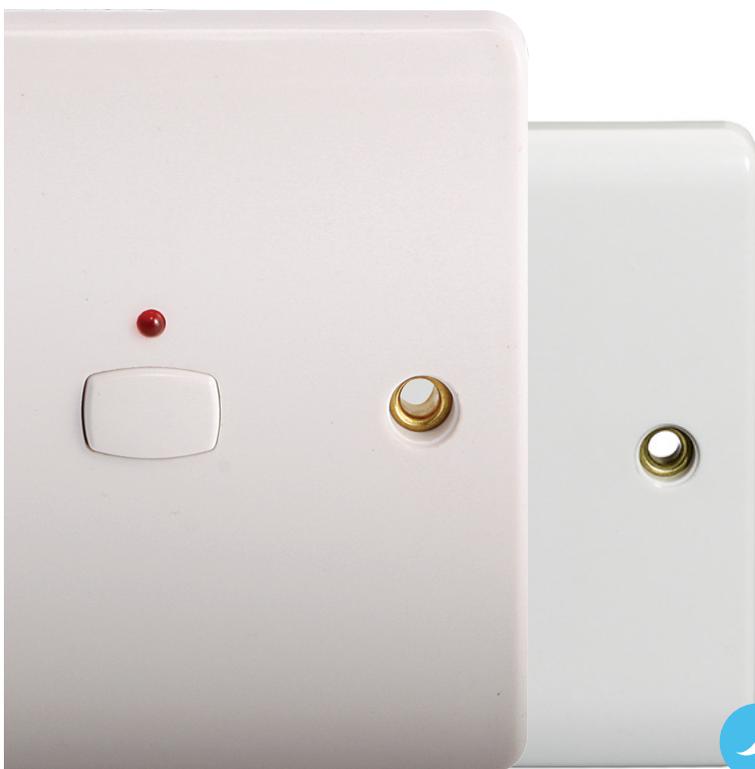

Control




### Product Description

The MiHome slave switch operates in conjunction with the Master to provide 2-way light switching for example where you want a switch at the top and bottom of a flight stairs for a particular light. Only the Live wire will be switched to the load. The master switch is a receive-only radio device operating in the 433MHz band. The slave operates by direct connection to the master switch.

### Technical Information

- Model: (1 Gang) MIHO043, MIHO044, MIHO045, MIHO046
- Model: (2 Gang) MIHO090, MIHO091, MIHO092, MIHO093
- Energenie recommends using dimmable LED bulbs
- Rating: 220-240V 50Hz, IA, 250W
- Terminal connections: L, LI, SLAVE
- Radio frequency: 433.92MHz

MiHome lets you take control of your heating, lighting and appliances from anywhere

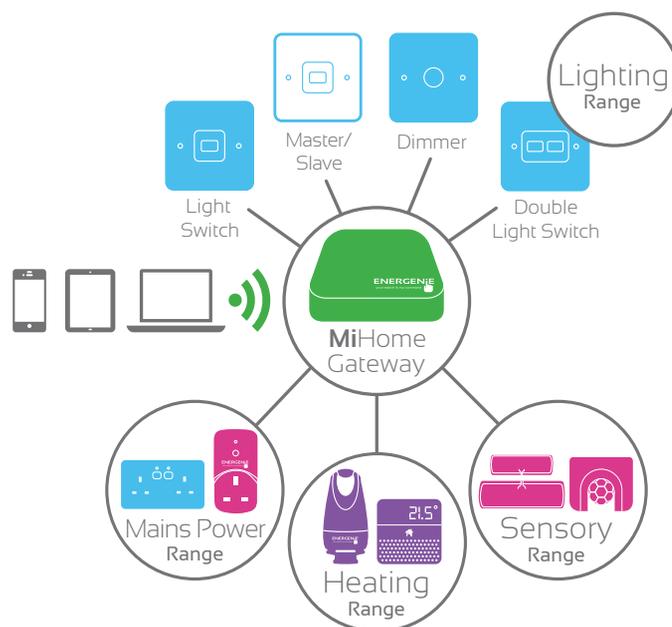

**ENERGENIE®**  
your switch is my command 

0844 412 7923  
[energenie4u.co.uk](http://energenie4u.co.uk)



Essential



Control



Monitor



Control & Monitor