

CABINET LOUDSPEAKERS

iPlay Wall Mount Loudspeakers

Plastic enclosure wall mount aluminium grill cabinet loudspeakers.

iPLAY 4T, 5T & 6


iPlay is one of our most popular lines, a good sound quality and a very keen price structure means they have many applications and are used in large quantities. The range includes 4", 5" and 6" loudspeakers with corresponding tweeters. iPlay 6 is designed only for low impedance speaker lines.

Available in black and white.




Technical Specifications	iPlay 4T	iPlay 5T	iPlay 6
Rated power	30 W (8 Ω)	35 W (8 Ω)	90 W (8 Ω)
Transformer power taps	16 W - 8 W - 4 W - 2 W - 8 Ω	30 W - 16 W - 8 W - 4 W - 8 Ω	
Sensitivity	87 dB (1 W/1 m)	89 dB (1 W/1 m)	87 dB (1 W/1 m)
Maximum SPL	103 dB (Pmax/1 m) at 8137 Hz	109 dB (Pmax/1 m) at 5573 Hz	110 dB (Pmax/1 m) at 4711 Hz
Frequency response	110 Hz – 20 kHz	120 Hz – 20 kHz	70 Hz – 20 kHz
Dispersion at 1000 Hz	180° (H), 160° (V)	180° (H), 160° (V)	165° (H), 133° (V)
Driver dimensions	4" (101 mm) woofer, 1" (25 mm) tweeter	5" (127 mm) woofer, 1" (25 mm) tweeter	6" (152 mm) woofer, 1,5" (38 mm) tweeter
Dimensions	220 mm x 135 mm x 135 mm	240 mm x 165 mm x 160 mm	285 mm x 195 mm x 200 mm
Weight	1,6 kg	2,2 kg	3,2 kg
Material	Polypropylene housing with aluminum grill, U-bracket – steel	Polypropylene housing with aluminum grill, U-bracket – steel	Polypropylene housing with aluminum grill, U-bracket – steel
Colour	Papyrus white (RAL 9018) or Black (RAL 9017)	Papyrus white (RAL 9018) or Black (RAL 9017)	Papyrus white (RAL 9018) or Black (RAL 9017)

iPlay 4T

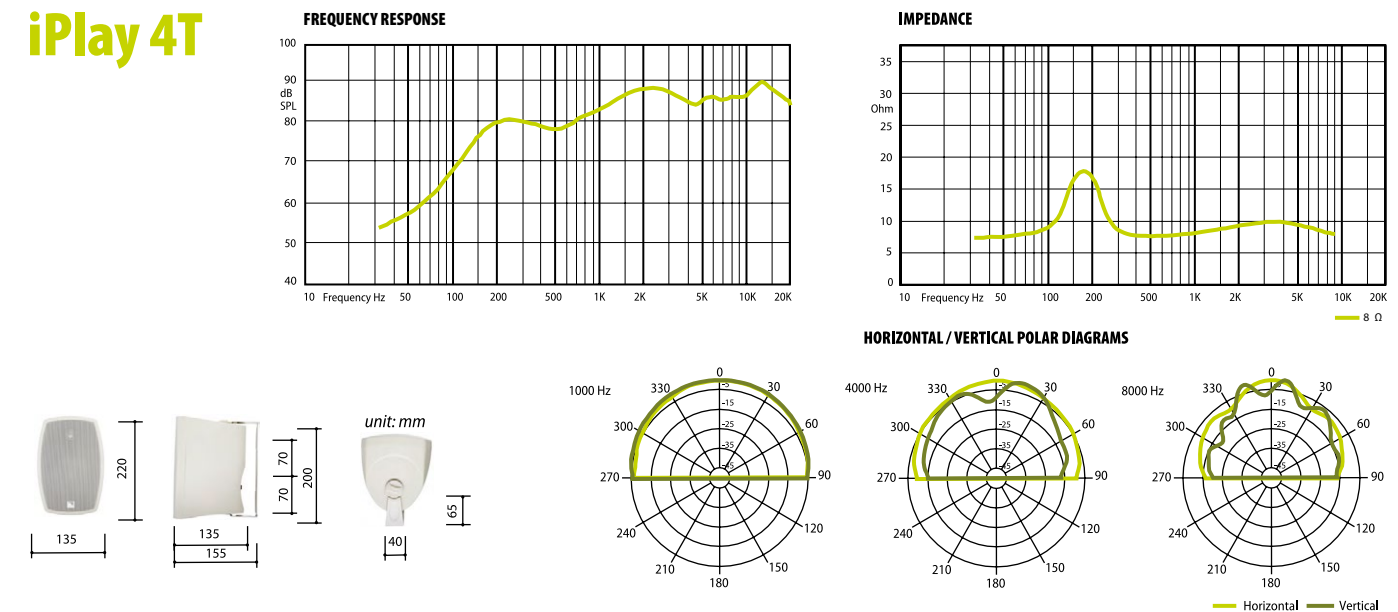

iPlay 5T

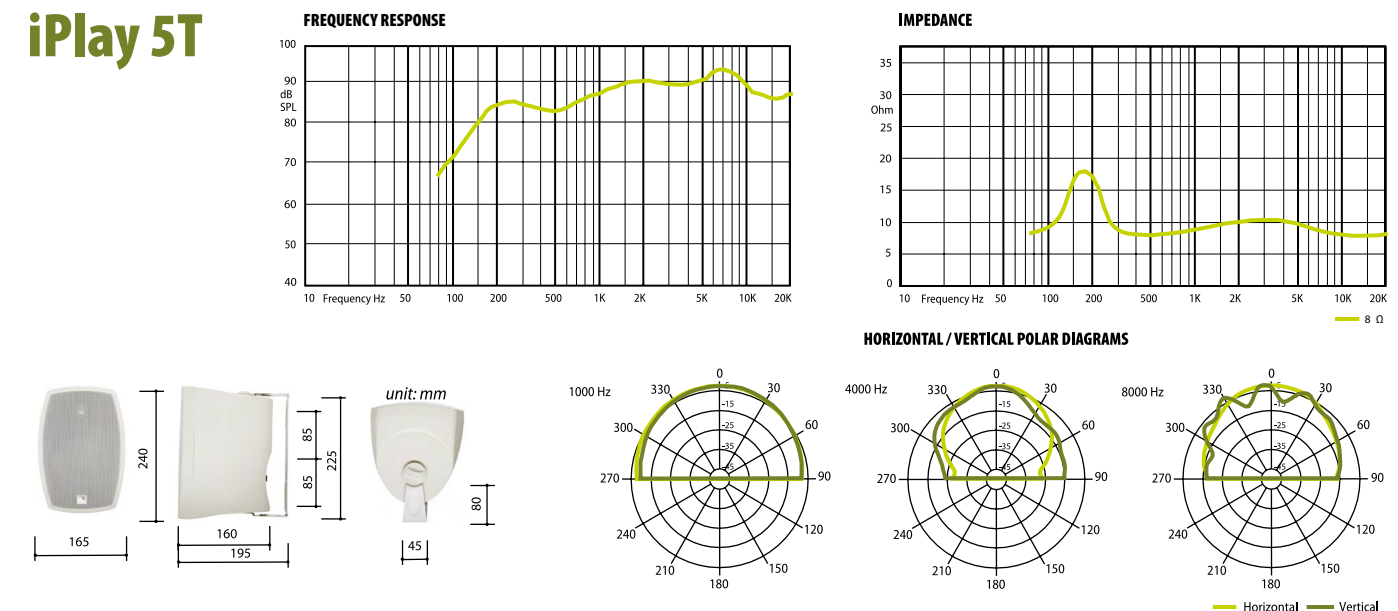

iPlay 6

