

Kelvin-Messleitung mit Zangen

- 4 Federkorbstecker, stapelbar, konfektioniert an flexibler PVC-Leitung 0,22 mm² und 2 Zangen
- diese Kelvin-Messleitung wurde speziell für Vierleitermessungen entwickelt
- Maulöffnung der Zange max. 15 mm
- den Warnhinweis WH 003 finden Sie unter www.schuetzinger.de

Best.-Nr.

KML 7528 / 2ZA / 4x0.22 / 70

- Leitung 0,22 mm²
PVC-isoliert
- Kontaktteile **vergoldet**
- Isolierteile PA (Polyamid)
PP (Polypropylen)
- **Farben** siehe Tabelle
- Schaltplan 1 ----- A
2 ----- B
3 ----- C
4 ----- D

Kelvin measuring lead with pincers

- 4 lamella-basket plugs, stackable, assembled on flexible PVC cable 0.22 mm² and 2 pincers
- this kelvin measuring lead has been especially developed for four-wire measurement
- pincer opening 15 mm max.
- please visit www.schuetzinger.de to find the warning notice WH 003

Order No.

KML 7528 / 2ZA / 4x0.22 / 70


- cable 0.22 mm²
PVC insulated
- contact parts **gold-plated**
- Insulation PA (Polyamid)
PP (Polypropylen)
- **colours** see table
- circuit 1 ----- A
2 ----- B
3 ----- C
4 ----- D



WH 003



WH 003

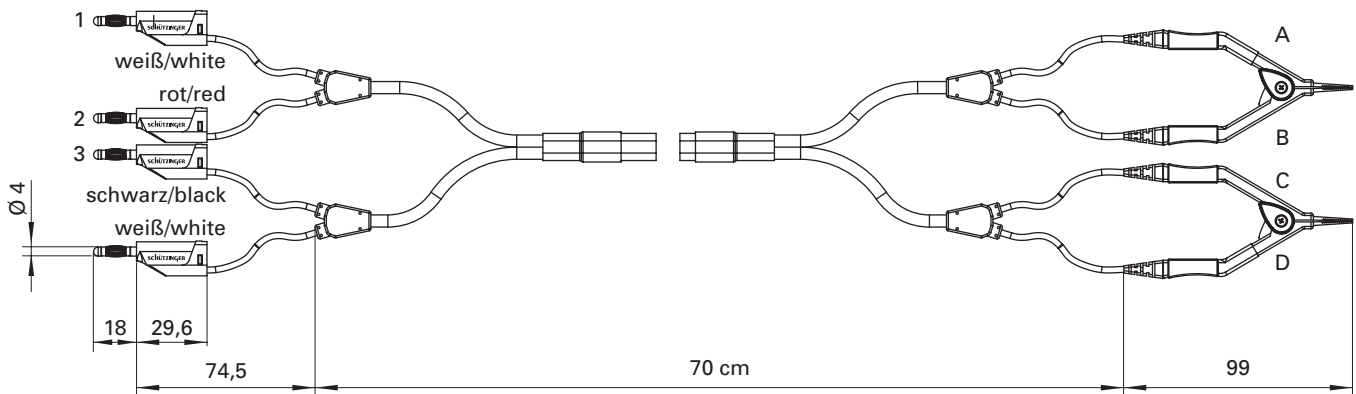

Allgemeine Angaben

Best.-Nr. ¹⁾	KML 7528 / 2ZA / 4x0.22 / 70 Kontaktteile vergoldet
Farben	schwarz/rot/weiß
Längen	70 cm
Technische Daten	
Leitung	PVC-isoliert 0,22 mm ²
Durchgangswiderstand	90 mΩ
Bemessungsspannung ²⁾	30 V _{AC} / 60 V _{DC}
Bemessungsstrom ²⁾	1 A per Leitung

General information

Order No. ¹⁾	KML 7528 / 2ZA / 4x0.22 / 70 contact parts gold-plated
colours	black/red/white
lengths	70 cm
Technical data	
cable	PVC insulated 0.22 mm ²
transition resistance	90 mΩ
rated voltage ²⁾	30 V _{AC} / 60 V _{DC}
rated current ²⁾	1 A per lead

¹⁾ andere Kontaktoberflächen, Farben und Längen auf Anfrage
²⁾ bei normalen Umgebungstemperaturen

¹⁾ other contact platings, colours and lengths on request
²⁾ at normal ambient temperatures