



ULTRA ROBUST QUALITY




TRIPOD STAND AVAILABLE



LIGHTWEIGHT AT ONLY 675G

SLR-1300 - INDUSTRIAL SITE LIGHT

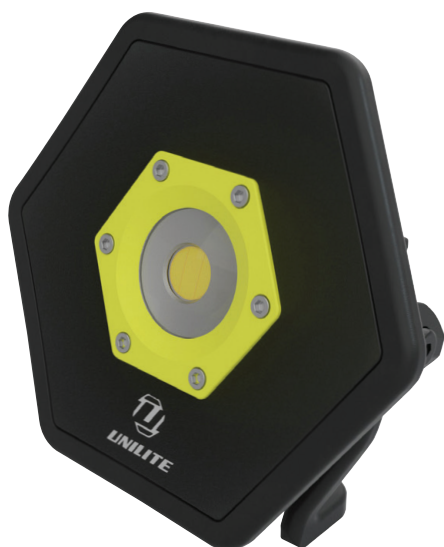

1300
LUMEN
OUTPUT

2-8½
HOURS
RUNTIME


49
METRE
BEAM RANGE

IP65
DUST + WATER
RESISTANCE

- Super bright 1300 Lumen white COB LED
- Super tough aluminium structure
- Built in aluminium heat sink
- 180° adjustable handle
- IK07 shock resistant
- IP65 dust + water resistant
- DC-USB rechargeable
- 7 hours charge time



180° ADJUSTABLE HANDLE/STAND

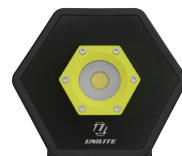

TOUGH ALUMINIUM STRUCTURE

BATTERY 3.7v 5200mAh Li-ion Rechargeable Battery
WEIGHT 675g
DIMENSIONS 49 x 184 x 194mm