

MASTER CARTON: 12/1/1
UPC: 784644228265
PRODUCT SECTION: AUDIOPIPE
SUBSECTION: HORNS
GIFTBOX SIZE: 10.5" X 11" X 6"

Audiopipe®
WWW.AUDIOPIPE.COM

APH-10610BO-H

HIGH FREQUENCY HORN

2" EXIT THROAT



SPECIFICATIONS

- High Frequency Horn
- ABS Horn
- Bolt-on Fitting
- Exit Throat Size: 2"
- Overall Dimensions:
10.4"(H) x 6"(W) x 10.7"(D)
- Mounting depth: 10"

10" X 6"
**BOLT
ON**



AUDIOPIPE



SERVICE & SUPPORT
Audiopipe offers expert knowledge and first-class service on all products and repairs.
1-877-AUDIOPIPE

MASTER CARTON: 20/1/1
UPC: 784644227978
PRODUCT SECTION: AUDIOPIPE
SUBSECTION: TWEETERS
GIFTBOX SIZE: 6.5" X 3.5" X 2"

Audiopipe®
WWW.AUDIOPIPE.COM

APHE-T650

SUPER HIGH FREQUENCY TITANIUM TWEETER



**250W
MAX.**

SPECIFICATIONS

- 250 Watts Power (P.M.P.O.)
- 125 Watts Power (R.M.S.)
- Frequency Response: 3K-20KHz
- 1" High Temperature Kapton Voice Coil
- Sensitivity: 105dB
- Impedance: 4 Ohms
- Mounting Depth: Φ 59mm (2-5/16")
- 24.5x6mm NdFeB Magnet Structure

SOLD IN PAIRS



**Mylar Crossover
Capacitor Included**

AUDIOPIPE




SERVICE & SUPPORT
Audiopipe offers expert knowledge and first-class service on all products and repairs.
1-877-AUDIOPIPE

MASTER CARTON: 20/1/1
UPC: 784644228289
PRODUCT SECTION: AUDIOPIPE
SUBSECTION: ACCESSORIES
GIFTBOX SIZE: 12" X 10" X 2.5"

Audiopipe®
WWW.AUDIOPIPE.COM

APMB-RING-6

6.5" PLASTIC SPEAKER SPACER RING

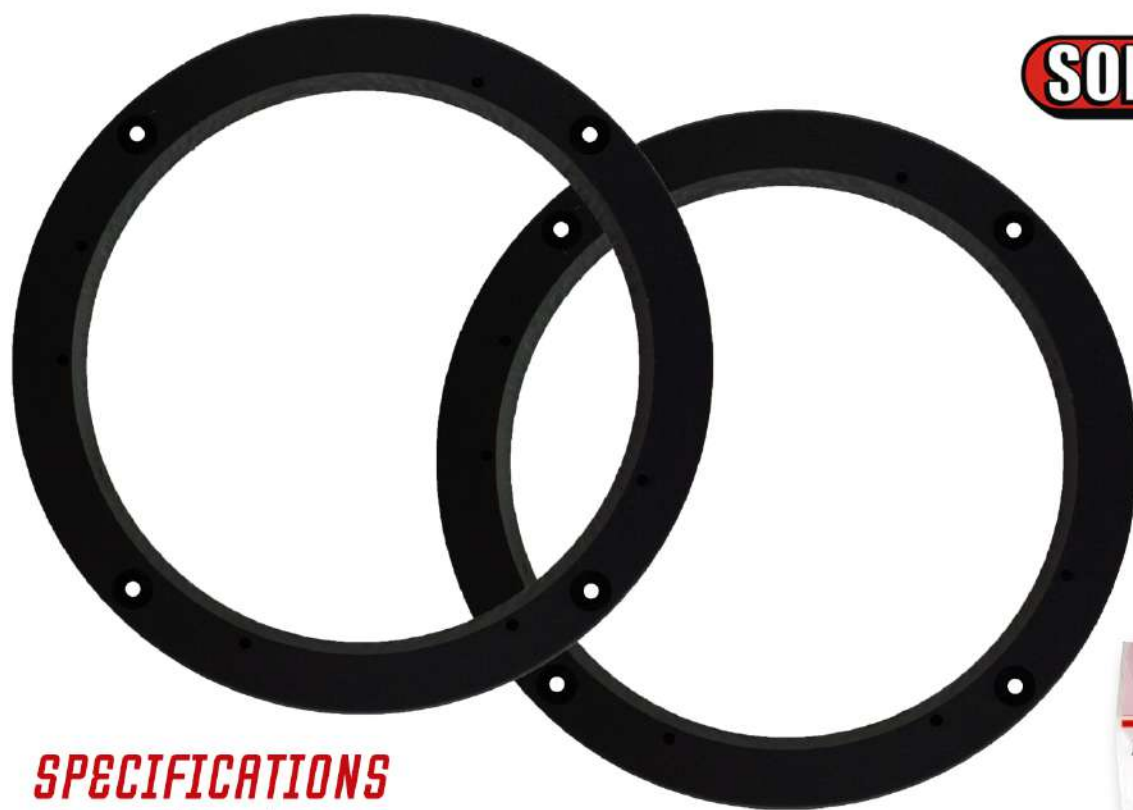

SOLD IN PAIRS

SPECIFICATIONS

- Inner Diameter: 5-7/8"
- Made From ABS Plastic
- 1-inch Allows Extra Mounting Depth

**EXCLUSIVELY MADE TO FIT OUR
APMB DIE CAST BASKET MODELS**



AUDIOPIPE




SERVICE & SUPPORT
Audiopipe offers expert knowledge and first-class service on all products and repairs.
1-877-AUDIOPIPE

MASTER CARTON: 20/1/1
UPC: 784644228296
PRODUCT SECTION: AUDIOPIPE
SUBSECTION: ACCESSORIES
GIFTBOX SIZE: 12" X 10" X 2.5"

Audiopipe®
WWW.AUDIOPIPE.COM

APMB-RING-8

8.5" PLASTIC SPEAKER SPACER RING

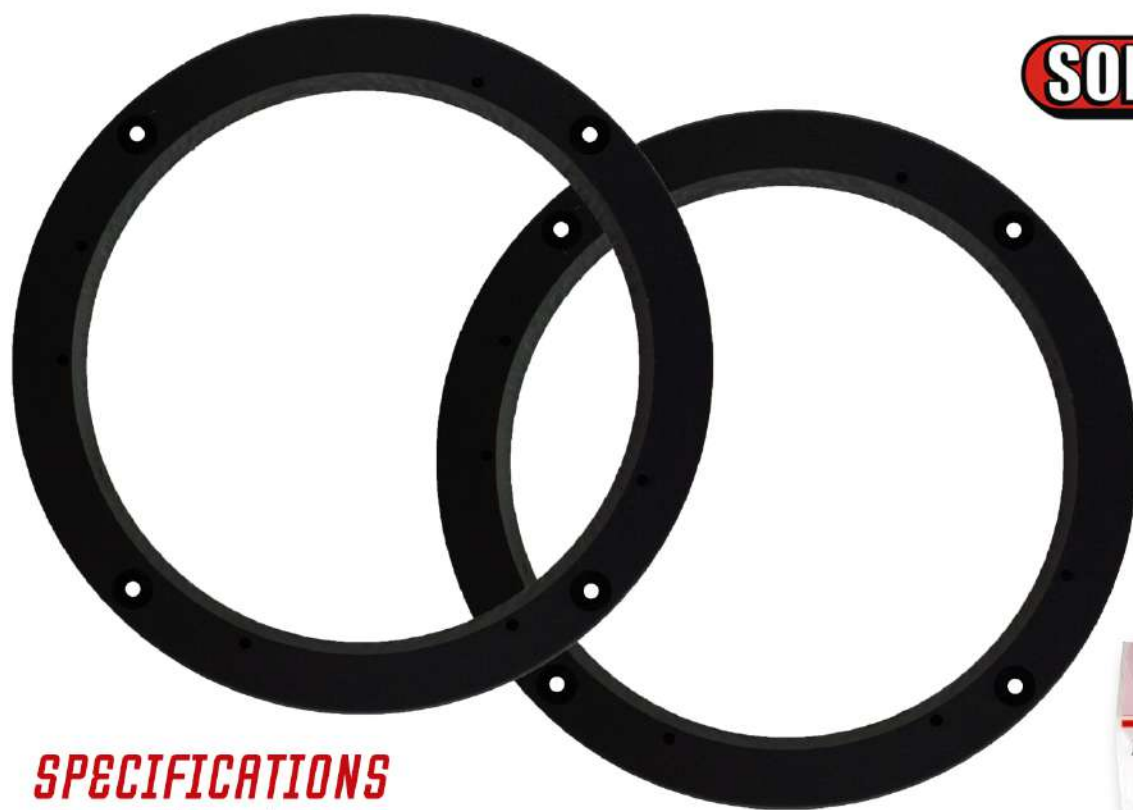

SOLD IN PAIRS

SPECIFICATIONS

- Inner Diameter: 7-7/8"
- Made From ABS Plastic
- 1-inch Allows Extra Mounting Depth

**EXCLUSIVELY MADE TO FIT OUR
APMB DIE CAST BASKET MODELS**



AUDIOPIPE



SERVICE & SUPPORT
Audiopipe offers expert knowledge and first-class service on all products and repairs.
1-877-AUDIOPIPE

MASTER CARTON: 20/1/1
UPC: 784644228210
PRODUCT SECTION: AUDIOPIPE
SUBSECTION: TWEETERS
GIFTBOX SIZE: 5" X 4" X 3.5"

Audiopipe®
WWW.AUDIOPIPE.COM

ATQ-300HF

1" PHENOLIC SUPER TWEETER



SPECIFICATIONS

- 150 Watts Power (P.M.P.O.)
- 75 Watts Power (R.M.S.)
- Frequency Response: 1000-20KHz
- Sensitivity: 105dB
- Impedance: 8 Ohms
- Resin Film Diaphragm
- 1" High Temperature Kapton Voice Coil
- Mounting Depth: 42mm (1-11/16")
- 11 Oz Magnet Structure
- 80mm x 15mm Ferrite Magnet

1"

150W

MAX Power



AUDIOPIPE



SERVICE & SUPPORT
Audiopipe offers expert knowledge and first-class service on all products and repairs.
1-877-AUDIOPIPE

NIPPON AMERICA GROUP
WWW.NIPPONAMERICA.COM



MASTER CARTON: 4/1/1

UPC: 784644228623

PRODUCT SECTION:

Audio

SUBSECTION:

Megaphone

GIFT BOX SIZE: 10" x 14" x 10"

ER-1091BT

Megaphone w/ Wireless Music Stream




**Recorder
& Siren**



**Rechargeable
Lithium
Battery**



12V Input

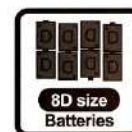

SPECIFICATIONS:

- Dry Cell or Rechargeable Battery Operation
- All ABS Body, Sturdy Yet Light Weight
- Built-in Siren and Music
- 120 seconds Voice Recording Function
- Support U-disk
- Support Playing MP3, WAV
- Support Wireless Music Stream
- Power Output: 25W Rated / 50W Max
- Voice Range: 0.7-1 km
- Power Source: 8 x "D" Cells
- Battery Life: 8-10 hrs
- Working Voltage: DC-12V
- Dimensions: Horn Dia.230mm, Length 350mm
- Weight: 1.21kg without cells

**50 Watts
Max**



NIPPON AMERICA GROUP
WWW.NIPPONAMERICA.COM



MASTER CARTON: 60/1/1

UPC: 784644759363

PRODUCT SECTION:

Video & Audio


SUBSECTION:

Accessories

GIFT BOX SIZE: 5" x 3.5" x 3.5"

HD-DIGI-ANAD

Digital to Analog Audio Converter

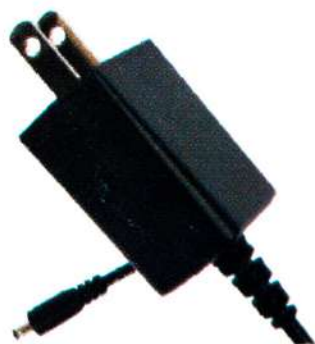

**AC/DC Adaptor
included**

Digital



SPECIFICATIONS:

- Converts S/PDIF or Optical (Toslink) to analog R/L Audio signal
- Supports 2 channels LPCM digital audio only
- Supports sampling rate at 32, 44.1, 48 and 96KHz
- Input: S/PDIF x 1, Toslink x 1
- Output: L/R Audio x 1, 3.5mm Audio x 1
- Dimensions: 76 x 56 x 22mm (2.99" x 2.20" x 0.87")
- Weight: 47g (0.1 Lbs)
- **Built in conversion module for movies with Enhanced Sound Programming**



NIPPON AMERICA GROUP
WWW.NIPPONAMERICA.COM



MASTER CARTON: 125/1/1

UPC: 784644758267

PRODUCT SECTION:

Video & Audio

SUBSECTION:

Accessories

GIFT BOX SIZE: 5.5" x 4.5" x 1.5"

RSS-1045-IR

Wireless IR Remote Extender

Wireless RF signals operate between the transmitter and receiver, allowing you to move around freely and still be in control of your IR-enabled equipment remotely up to 100 meters away, depending on surrounding obstructions.

38/56 KHz
Carrier frequency

433.92 MHz
Transmission frequency



Receiver Specifications:

- Power input: 2xAA 1.5V non-rechargeable alkaline batteries (not included), or rechargeable power bank (included)
- RF range: Up to 100m free field, up to 30m through walls and ceilings
- RF Frequency: 433.92MHz
- IR Frequency range: 38/56KHz
- IR reception angle: 60° (+/- 30° from center)
- Dimensions: 65 x 50 x 30mm



Transmitter Specifications:

- Power input: 2xAA 1.5V non-rechargeable alkaline batteries (not included), or rechargeable power bank (included)
- IR reception range: 8 meters
- Dimensions: 65 x 50 x 30mm



MASTER CARTON: 20/1/1
UPC: 784644417942
PRODUCT SECTION: AUDIOPIPE
SUBSECTION: PROCESSORS
GIFTBOX SIZE: 8" X 8" X 2.75"

Audiopipe®
WWW.AUDIOPIPE.COM

SPLIT-3113RMT

AUDIO SIGNAL SPLITTER



RCA
1 IN / 3 OUT
10V Audio Signal Line Driver

WITH REMOTE BASS KNOB



SPECIFICATIONS

- Input Impedance: 47K Ohms
- Input Sensitivity: 260mV
- S/N Ratio: >95dB
- Output Level (10KHz)
- Output Impedance: 1K Ohms
- Channel Resolution: >60dB
- Harmonics Distortion: 0.009%
- Frequency Response: 20-20,000Hz
- Output Gain: 12dB



AUDIOPIPE



SERVICE & SUPPORT
Audiopipe offers expert knowledge and first-class service on all products and repairs.
1-877-AUDIOPIPE