

# Wall mounted Multi-Format HDBaseT Transmitters, 3 Inputs to 1 HDBaseT Output

MFT-31V




## MFT-31V

These are ideal for classroom and meeting room environments where a quick and simple connection from a laptop, mobile or any other devices is required.

## FEATURES

- 2x HDMI inputs
- 1x VGA video input (with audio)
- 1x HDBaseT output (70m @ 1080p, 40m @ 4K30)
- RS232 control (Tx Rx) and data pass through
- IR Eye data pass through
- EDID management
- Built in IR Eye (IR receiver) MFT-31C IR learning for Display On/Off control
- LED indication for selected input
- LED indication for Link status to HDBaseT receiver
- Auto/Manual selection

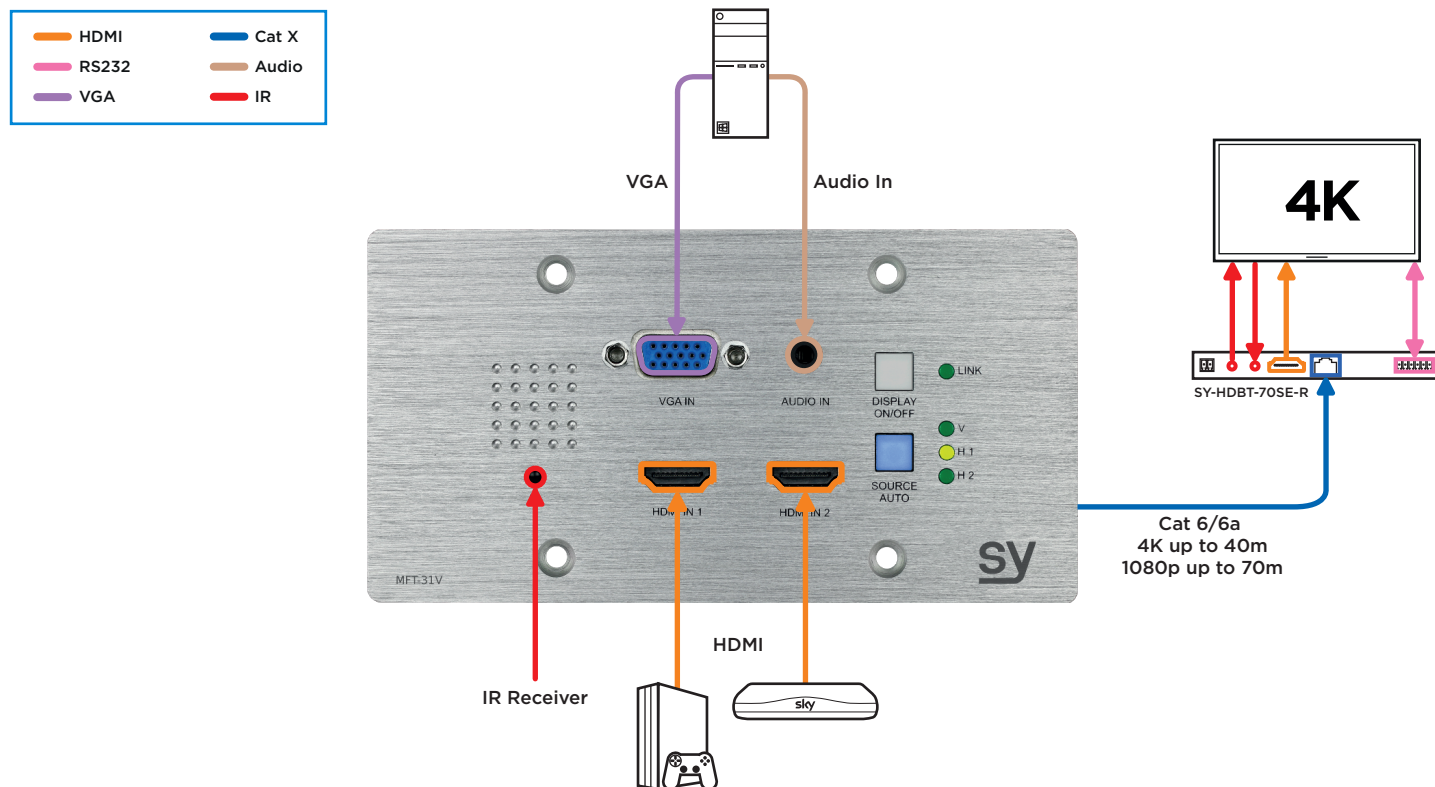

# Wall mounted Multi-Format HDBaseT Transmitters, 3 Inputs to 1 HDBaseT Output

MFT-31V



## SPECIFICATIONS

<b>PART NUMBER</b>	SY-MFT-31V	
<b>VIDEO RESOLUTIONS/FORMATS</b>	VESA and SMPTE 480p to 2160p with 3D. All HDMI resolutions to 3840x2160p @60Hz 4:2:0, 480p@60Hz 1080p@24Hz 4K@24Hz, 576p@50Hz 1080p@50Hz 4K@30Hz, 720p@60Hz 1080p@60Hz 4K@60Hz YUV4:2:0 All PC resolutions to 1920x1200@60Hz	
<b>BANDWIDTH</b>	10.2Gbps	
<b>HDCP</b>	1.4 & 2.2	
<b>INPUTS</b>	<b>Video</b> 1x HDMI type A 1x VGA	<b>Audio</b> L+R 3.5mm Stereo Jack. 20Hz - 20kHz, 1.5Vrms max.
<b>MAXIMUM HDBaseT RANGE</b>	40m - 4K60 4:2:0 70m - 1080p60	
<b>CONTROL</b>	RS232 IR	
<b>POWER SUPPLY</b>	24V DC, 1.25A	
<b>POWER CONSUMPTION</b>	5W	
<b>WEIGHT AND DIMENSIONS</b>	<b>Weight (net)</b> 0.245kg	<b>Size (WHD)</b> UK: 146 x 86 x 43mm EU: 151 x 80 x 43mm
<b>WHAT'S IN THE BOX</b>	1x MFT-31V User's Manual	

"HDMI, the HDMI Logo, and High-Definition Multimedia Interface are trademarks or registered trademarks of the HDMI Licensing LLC in the United States and other countries"  
Details subject to change with no prior notice.