



BIANCA

TRIPLE HEAD TALL POST LANTERN

IP44
RATED5 YEAR
GUARANTEE

TECHNICAL

* Lamps not included

Colour temp	Product code	Wattage	Lamp type
N/A	CZ-25149-BLK	60W Max	3 x E27 GLS*


GENERAL

Input voltage	220-240V
Constructional material	Polycarbonate & Glass
Class	2
IP rating	IP44
Weight (kg)	6kg
Fixings & Instructions supplied	Yes

PRODUCT DATA

Product code	Description	Colour	EAN
CZ-25149-BLK	Bianca Triple Head Tall Post Lantern	Black	5020024605840

Dimensions

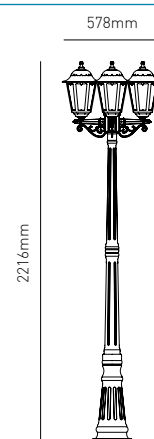

Energy efficiency rating

