


Candle

- 2,000hr Lamp Life
- Clear Finish
- UV Stop Glass
- Dimmable
- Internal Fuse
- B22, B15, E27 & E14 Caps
- 25W - 60W Replacements

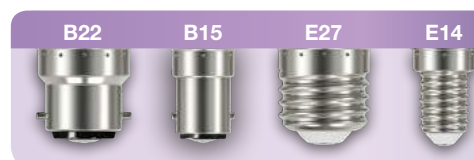

CANDLE - 2,000 HOURS

Box Code	Blister Code	Finish	Cap	Watt. & Equiv.	Lumen	Colour Temp.	Dimmable	Lamp Dims. (mm)	In/Out Box	In/Out Blister
S11857	S11859 (2pk)	Clear	B22	20W/25W	235lm	2700K	✓	35x95	10/100	10/100
S11917	S11911 (2pk)	Clear	B15	20W/25W	235lm	2700K	✓	35x95	10/100	10/100
S11916	S11910 (2pk)	Clear	E27	20W/25W	235lm	2700K	✓	35x95	10/100	10/100
S11858	S11860 (2pk)	Clear	E14	20W/25W	235lm	2700K	✓	35x95	10/100	10/100
S10116	S11861 (2pk)	Clear	B22	30W/40W	405lm	2700K	✓	35x95	10/100	10/100
S10117	S11862 (2pk)	Clear	B15	30W/40W	405lm	2700K	✓	35x95	10/100	10/100
S10118	S11863 (2pk)	Clear	E27	30W/40W	405lm	2700K	✓	35x95	10/100	10/100
S10119	S11864 (2pk)	Clear	E14	30W/40W	405lm	2700K	✓	35x95	10/100	10/100
S10120	S11865 (2pk)	Clear	B22	46W/60W	700lm	2700K	✓	35x95	10/100	10/100
S10121	S11866 (2pk)	Clear	B15	46W/60W	700lm	2700K	✓	35x95	10/100	10/100
S10122	S11867 (2pk)	Clear	E27	46W/60W	700lm	2700K	✓	35x95	10/100	10/100
S10123	S11868 (2pk)	Clear	E14	46W/60W	700lm	2700K	✓	35x95	10/100	10/100

