


G4, G9 & MR16

- 2,000hr Lamp Life
- Clear Finish
- UV Stop Glass
- Dimmable
- Internal Fuse
- G4, G9 & MR16 Caps
- 20W - 50W Replacements

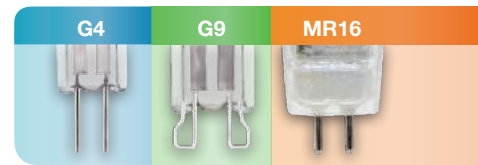

G4 - 2,000 HOURS

Box Code	Blister Code	Finish	Cap	Watt. & Equiv.	Lumen	Colour Temp.	Dimmable	Lamp Dims. (mm)	In/Out Box	In/Out Blister
S10109	S11850 (2pk)	Clear	G4	14W/20W	235lm	2900K	✓	8x32	10/1000	10/100

G9 - 2,000 HOURS

Box Code	Blister Code	Finish	Cap	Watt. & Equiv.	Lumen	Colour Temp.	Dimmable	Lamp Dims. (mm)
S10110	S11851 (2pk)	Clear	G9	33W/40W	460lm	2700K	✓	13x47

MR16 - 2,000 HOURS

Box Code	Blister Code	Finish	Cap	Watt. & Equiv.	Lumen	Colour Temp.	Dimmable	Lamp Dims. (mm)
S10111	S11852 (2pk)	Clear	MR16	40W/50W	460lm	2700K	✓	50x47

