




**SPECIFICATION
CONTROL DRAWING**
Crystal Resonator

FREQUENCY
16.000000MHz

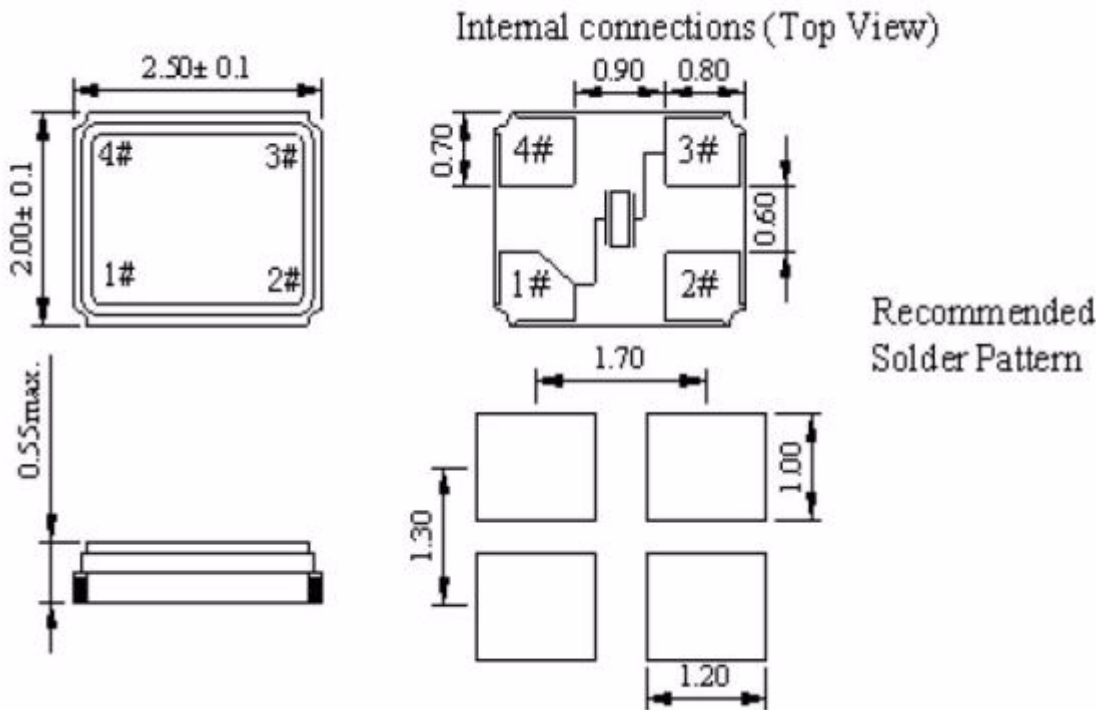

Holder Style	25x2x05 4-pad
Mode	Fundamental
Adjustment Tolerance	± 20 PPM at 25°C
Temperature Stability	± 20 PPM
Operating Temp. Range	-40°C to +85°C
Load Capacitance	8 pF
ESR	60 Max Ohm
Static Capacitance (C0)	Unspecified pF
Ageing	+/-3ppm 1st Year Max
Marking	AEL16.0 ww/yy

Amdt Date	Change Note	AEL Code	
		X16M000000S207	
		Issue Ref	A