




# SPECIFICATION CONTROL DRAWING Crystal Resonator

FREQUENCY
26.000000MHz

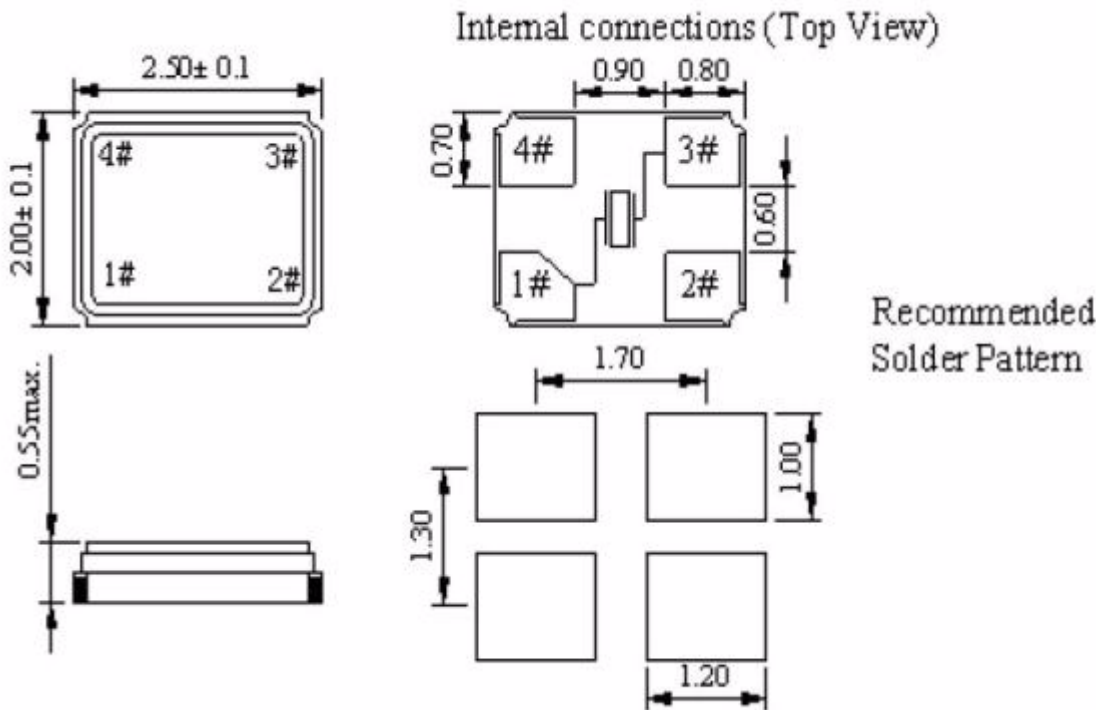

Holder Style	25x2x05 4-pad
Mode	Fundamental
Adjustment Tolerance	± 15PPM at 25°C
Temperature Stability	± 15 PPM
Operating Temp. Range	-40°C to +85°C
Load Capacitance	9 pF
ESR	60 Max Ohm
Static Capacitance (C0)	Unspecified pF
Ageing	+/-5ppm 1st Year Max
Marking	AEL26.000 ww/yy

Amdt	Date	Change Note	AEL Code
			X26M000000S202
		Issue Ref	A