




SPECIFICATION CONTROL DRAWING Crystal Resonator

FREQUENCY

32.768000kHz

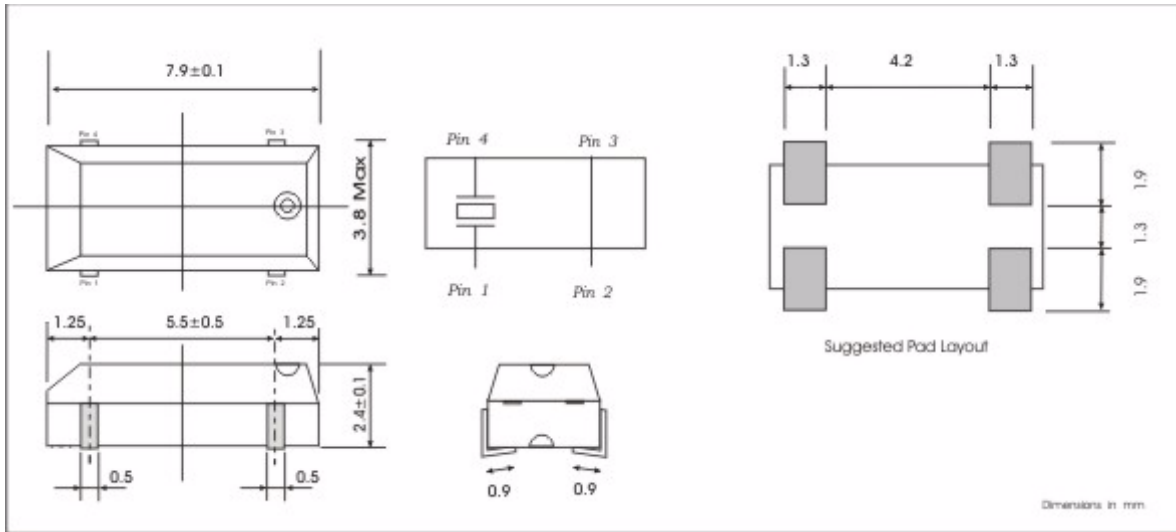

Holder Style	8 x 4mm 4 Pad
Mode	Fundamental
Adjustment Tolerance	± 20PPM at 25°C
Operating Temp. Range	-40°C to +85°C
Load Capacitance	12.5 pF
ESR	50K Max Ohm
Drive Level	1.0uW Max mW
Static Capacitance (C0)	0.9 Typ pF
Dynamic Capacitance (C1)	2.0fF Typ fF
Ageing	+/-5ppm/ per yr Max
Marking	32.768/datecode

Amdt Date	Change Note	AEL Code
	260C Reflow	X32K768S115
		Issue Ref A