




**SPECIFICATION  
CONTROL DRAWING  
Crystal Resonator**

FREQUENCY
32.768000kHz

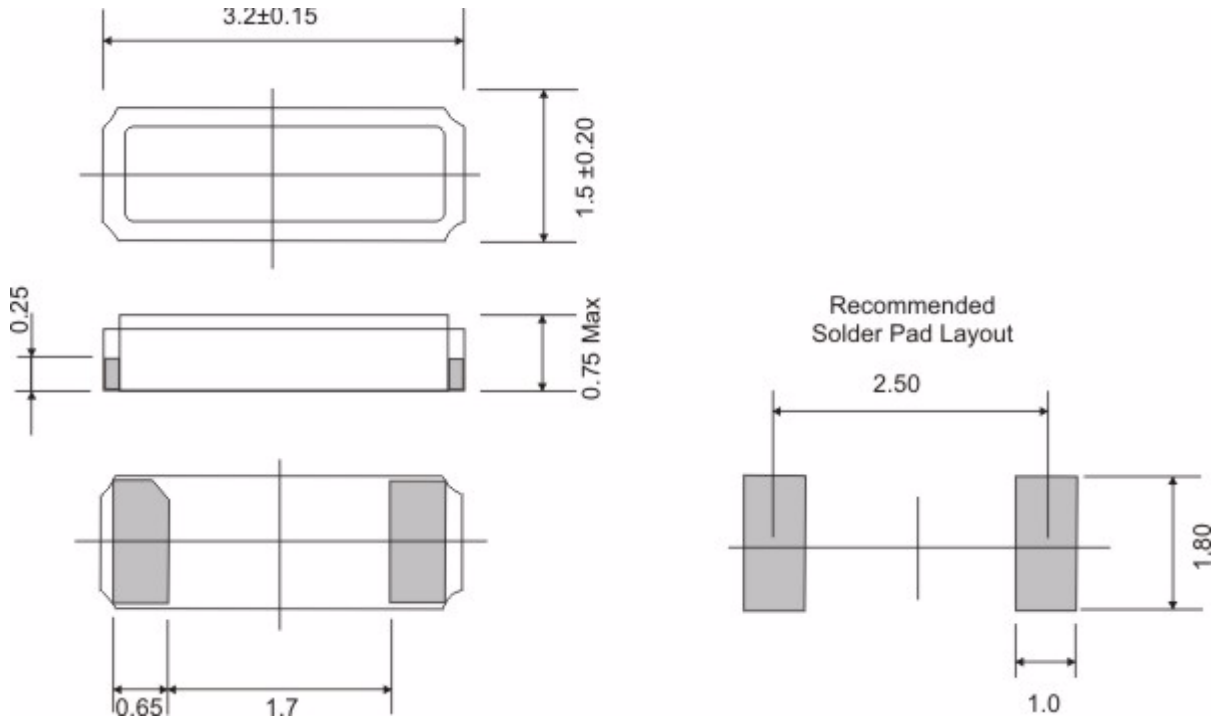

Holder Style	3,2 x 1,5mm
Mode	Fundamental
Adjustment Tolerance	$\pm 10$ PPM at 25°C
Operating Temp. Range	-40°C to +85°C
Load Capacitance	7 pF
ESR	70000 Max Ohm
Static Capacitance (C0)	Unspecified pF
Ageing	+/-5ppm 1st Year Max
Marking	AE 32.768 WW/YY

Amdt Date	Change Note	AEL Code
		<b>X32K768S315</b>
		<b>Issue Ref</b> A