




**SPECIFICATION
CONTROL DRAWING**
Crystal Resonator

FREQUENCY
40.000000MHz

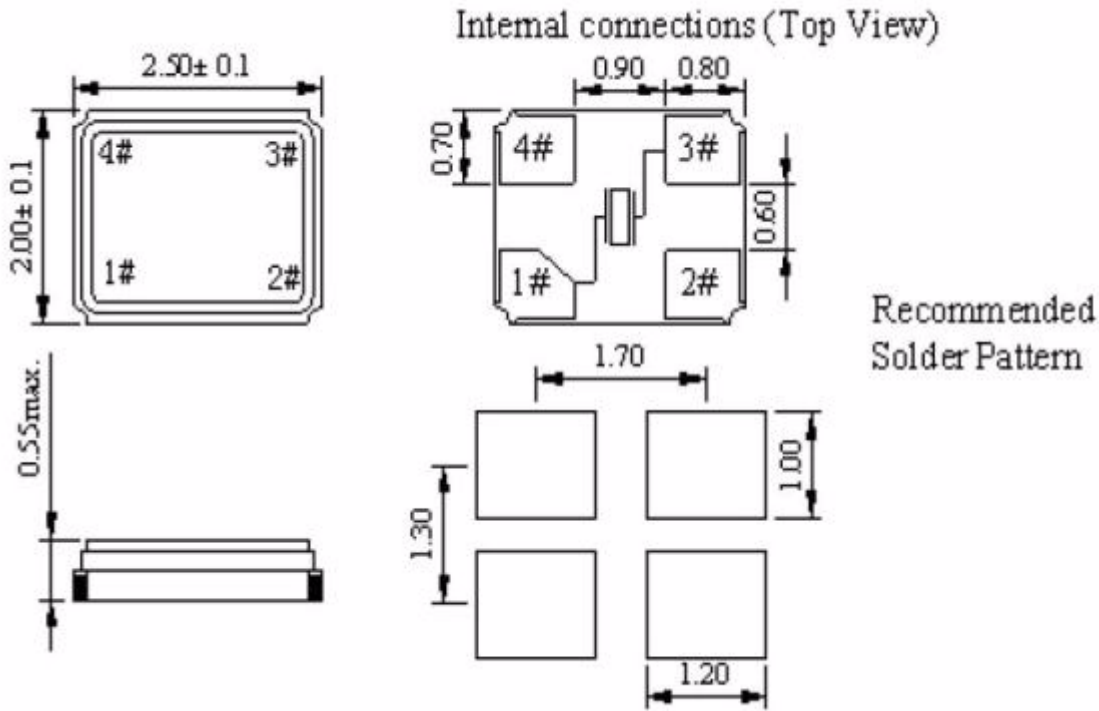

Holder Style	25x2x05 4-pad
Mode	Fundamental
Adjustment Tolerance	± 9 PPM at 25°C
Temperature Stability	± 15 PPM
Operating Temp. Range	-40°C to $+85^{\circ}\text{C}$
Load Capacitance	12 pF
ESR	60 Max Ohm
Static Capacitance (C0)	Unspecified pF
Ageing	± 3 ppm 1st Year Max
Marking	AEL40 WWYY

Amdt Date	Change Note	AEL Code
		X40M000000S203
		Issue Ref A