

 
B6 Series | Indicator Lights, Switch Size

PRODUCT CODE: B61121GL00000



sample image

Wiring diagrams



Terminal type



Body colour



Actuator colour



Rating

200 - 250 VAC

T120°C

VDE 710

GWT 850°C

GWT NO FLAME (less than 2 sec) 650°C

200-250 VAC

T65°C


UL496

CSA C22.2


Approvals




Dimensions (mm)

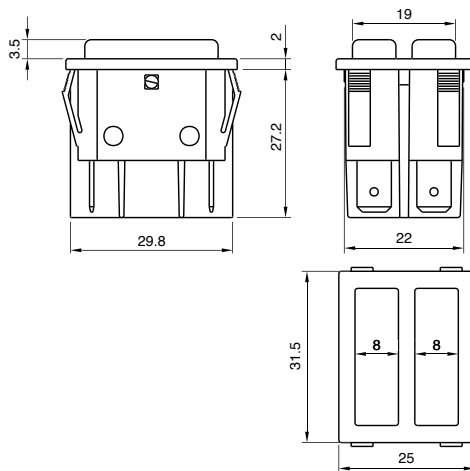

Terminals (mm)

 

Cut out (mm)

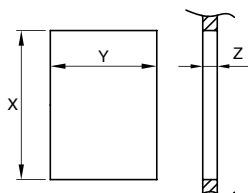

Z	Y	X
0,75 ... 1,25	22,0 ±0,2 0	30,0 0 -0,1
1,25 ... 2,0	22,0 ±0,2 0	30,2 0 -0,1
2,0 ... 3,0	22,0 ±0,2 0	30,6 0 -0,2
3,0 ... 4,0	22,0 ±0,2 0	30,8 0 -0,2