

## Z-TYPE Pre-printed wire markers

Z-Type markers are individual push-on markers used to identify wires and small cables permanently. The markers are manufactured using PVC and designed with an expanding profile, enabling each marker to accommodate a wide range of wire and cable sizes.

Z-Type markers are a simple, cost effective solution for many commercial wire identification applications,

The most popular colour option is white marker body with black marking and available as loose piece in boxes or on reels. Can also be supplied with a yellow marker body with black marking.

### Features and benefits

- Z-Type markers are a cost effective solution for many commercial wire identification applications
- Self-extinguishing
- Resistant to key industrial fluids, including those used in mass transit, aviation and military
- 9 sizes available covering wire diameters from 1.5mm to 12.7mm
- Applicator wands available for easy marker installation




## Z-Type Markers - straight cut in boxes

Ordering information - (the full range of part numbers are listed on the page opposite)

Part Number (WHITE)	Part Number (COLOURS)	Size	Pack Size	For Cable Dia (mm)	For Cable Size (mm <sup>2</sup> )	Applicator
058019.(legend)	05801(colour).(legend)	Z5	1000pcs	1.5 - 2.0	–	–
058119.(legend)	05811(colour).(legend)	Z7	1000pcs	2.0 - 3.2	1.0	1251
061519.(legend)	06151(colour).(legend)	Z9	1000pcs	2.5 - 4.0	1.5	1252
061619.(legend)	06161(colour).(legend)	Z11	1000pcs	2.9 - 4.7	2.5	1253
061719.(legend)	06171(colour).(legend)	Z13	1000pcs	3.4 - 5.7	4.0	1254
061819.(legend)	06181(colour).(legend)	Z15	1000pcs	3.8 - 6.3	6.0	1255
062019.(legend)	06201(colour).(legend)	Z18	500pcs	4.3 - 6.9	10.0	1256
062219.(legend)	06221(colour).(legend)	Z23	500pcs	5.5 - 8.9	16.0	–
062419.(legend)	06241(colour).(legend)	Z35	250pcs	7.9 - 12.7	25.0	–

(\* BS6231 Tri-Rated)

### Applicator wands

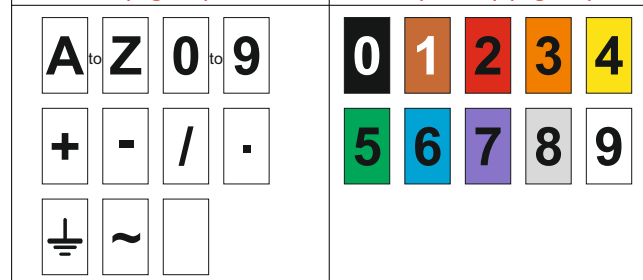

## Z-Type Marker Kits

Z-Type markers are available in easy to order bundles. A time saving solution when ordering your marker requirements, as everything you need is ordered using one part number.

- **KIT1** - supplied with letters A to Z and numbers 0 to 9 along with 50 compartment carry case
- **KIT2** - supplied with numbers 0 to 9
- **KIT3** - supplied with letters A to Z
- **C.KIT** - supplied with colour coded numbers 0 to 9
- **CL55-50** - 50 compartment carry case only



# Z-TYPE Pre-printed wire markers - ordering information

Printed Character	Z5 Part Number	Z7 Part Number	Z9 Part Number	Z11 Part Number	Z13 Part Number	Z15 Part Number	Z18 Part Number	Z23 Part Number	Z35 Part Number
A - Z 0 - 9	058019.KIT	058119.KIT	061519.KIT	061619.KIT	061719.KIT	061819.KIT	062019.KIT	062219.KIT	062419.KIT
0 - 9	058019.KIT2	058119.KIT2	061519.KIT2	061619.KIT2	061719.KIT2	061819.KIT2	062019.KIT2	062219.KIT2	062419.KIT2
A - Z	058019.KIT3	058119.KIT3	061519.KIT3	061619.KIT3	061719.KIT3	061819.KIT3	062019.KIT3	062219.KIT3	062419.KIT3

0	058019.0	058119.0	061519.0	061619.0	061719.0	061819.0	062019.0	062219.0	062419.0
1	058019.1	058119.1	061519.1	061619.1	061719.1	61819.1	062019.1	062219.1	062419.1
2	058019.2	058119.2	061519.2	061619.2	061719.2	61819.2	062019.2	062219.2	062419.2
3	058019.3	058119.3	061519.3	061619.3	061719.3	61819.3	062019.3	062219.3	062419.3
4	058019.4	058119.4	061519.4	061619.4	061719.4	61819.4	062019.4	062219.4	062419.4
5	058019.5	058119.5	061519.5	061619.5	061719.5	61819.5	062019.5	062219.5	062419.5
6	058019.6	058119.6	061519.6	061619.6	061719.6	61819.6	062019.6	062219.6	062419.6
7	058019.7	058119.7	061519.7	061619.7	061719.7	61819.7	062019.7	062219.7	062419.7
8	058019.8	058119.8	061519.8	061619.8	061719.8	61819.8	062019.8	062219.8	062419.8
9	058019.9	058119.9	061519.9	061619.9	061719.9	61819.9	062019.9	062219.9	062419.9

A	058019.A	058119.A	061519.A	061619.A	061719.A	061819.A	062019.A	062219.A	062419.A
B	058019.B	058119.B	061519.B	061619.B	061719.B	061819.B	062019.B	062219.B	062419.B
C	058019.C	058119.C	061519.C	061619.C	061719.C	061819.C	062019.C	062219.C	062419.C
D	058019.D	058119.D	061519.D	061619.D	061719.D	061819.D	062019.D	062219.D	062419.D
E	058019.E	058119.E	061519.E	061619.E	061719.E	061819.E	062019.E	062219.E	062419.E
F	058019.F	058119.F	061519.F	061619.F	061719.F	061819.F	062019.F	062219.F	062419.F
G	058019.G	058119.G	061519.G	061619.G	061719.G	061819.G	062019.G	062219.G	062419.G
H	058019.H	058119.H	061519.H	061619.H	061719.H	061819.H	062019.H	062219.H	062419.H
I	058019.I	058119.I	061519.I	061619.I	061719.I	061819.I	062019.I	062219.I	062419.I
J	058019.J	058119.J	061519.J	061619.J	061719.J	061819.J	062019.J	062219.J	062419.J
K	058019.K	058119.K	061519.K	061619.K	061719.K	061819.K	062019.K	062219.K	062419.K
L	058019.L	058119.L	061519.L	061619.L	061719.L	061819.L	062019.L	062219.L	062419.L
M	058019.M	058119.M	061519.M	061619.M	061719.M	061819.M	062019.M	062219.M	062419.M
N	058019.N	058119.N	061519.N	061619.N	061719.N	061819.N	062019.N	062219.N	062419.N
O	058019.O	058119.O	061519.O	061619.O	061719.O	061819.O	062019.O	062219.O	062419.O
P	058019.P	058119.P	061519.P	061619.P	061719.P	061819.P	062019.P	062219.P	062419.P
Q	058019.Q	058119.Q	061519.Q	061619.Q	061719.Q	061819.Q	062019.Q	062219.Q	062419.Q
R	058019.R	058119.R	061519.R	061619.R	061719.R	061819.R	062019.R	062219.R	062419.R
S	058019.S	058119.S	061519.S	061619.S	061719.S	061819.S	062019.S	062219.S	062419.S
T	058019.T	058119.T	061519.T	061619.T	061719.T	061819.T	062019.T	062219.T	062419.T
U	058019.U	058119.U	061519.U	061619.U	061719.U	061819.U	062019.U	062219.U	062419.U
V	058019.V	058119.V	061519.V	061619.V	061719.V	061819.V	062019.V	062219.V	062419.V
W	058019.W	058119.W	061519.W	061619.W	061719.W	061819.W	062019.W	062219.W	062419.W
X	058019.X	058119.X	061519.X	061619.X	061719.X	061819.X	062019.X	062219.X	062419.X
Y	058019.Y	058119.Y	061519.Y	061619.Y	061719.Y	061819.Y	062019.Y	062219.Y	062419.Y
Z	058019.Z	058119.Z	061519.Z	061619.Z	061719.Z	061819.Z	062019.Z	062219.Z	062419.Z

+	058019.+	058119.+	061519.+	061619.+	061719.+	061819.+	062019.+	062219.+	062419.+
-	058019.-	058119.-	061519.-	061619.-	061719.-	061819.-	062019.-	062219.-	062419.-
/	058019./	058119./	061519./	061619./	061719./	061819./	062019./	062219./	062419./
.	058019.DOT	058119.DOT	061519.DOT	061619.DOT	061719.DOT	061819.DOT	062019.DOT	062219.DOT	062419.DOT
⊥	058019.EA	058119.EA	061519.EA	061619.EA	061719.EA	061819.EA	062019.EA	062219.EA	062419.EA
~	058019.PH	058119.PH	061519.PH	061619.PH	061719.PH	061819.PH	062019.PH	062219.PH	062419.PH
BLANK	058019.BL	058119.BL	061519.BL	061619.BL	061719.BL	061819.BL	062019.BL	062219.BL	062419.BL

0	058010.0	058110	061510.0	061610.0	061710.0	061810.0	062010.0	062210.0	062410.0
1	058011.1	058111.1	061511.1	061611.1	061711.1	061811.1	062011.1	062211.1	062411.1
2	058012.2	058112.2	061512.2	061612.2	061712.2	061812.2	062012.2	062212.2	062412.2
3	058013.3	058113.3	061513.3	061613.3	061713.3	061813.3	062013.3	062213.3	062413.3
4	058014.4	058114.4	061514.4	061614.4	061714.4	061814.4	062014.4	062214.4	062414.4
5	058015.5	058115.5	061515.5	061615.5	061715.5	061815.5	062015.5	062215.5	062415.5
6	058016.6	058116.6	061516.6	061616.6	061716.6	061816.6	062016.6	062216.6	062416.6
7	058017.7	058117.7	061517.7	061617.7	061717.7	061817.7	062017.7	062217.7	062417.7
8	058018.8	058118.8	061518.8	061618.8	061718.8	061818.8	062018.8	062218.8	062418.8
9	058019.9	058119.9	061519.9	061619.9	061719.9	061819.9	062019.9	062219.9	062419.9
0 - 9	05801C.C.KIT	05811C.C.KIT	06151C.C.KIT	06161C.C.KIT	06171C.C.KIT	06181C.C.KIT	06201C.C.KIT	06221C.C.KIT	06241C.C.KIT