



# Get Ultimate Key Precision and Advanced Key Security

## Brady SafeKey Lockout Padlocks




In the last 50 years we've seen a manufacturing technology boom matched only by the industrial revolution. With these advances, lockout needs have evolved. Lock in to ultimate key precision and advanced key security for years to come with SafeKey Lockout Padlocks. You'll get:

- 700% more unique key possibilities
- Forward-thinking design for more control in your lockout program
- Solutions for your simple to highly complex lockout needs
- Plus easy operation, fast identification and excellent durability

### See the difference in the details

Product innovations are only as good as the benefits they provide. See the SafeKey Padlock difference:

- **Enhanced security** with two side-locking bars
- **Extra durability** in industrial environments with one-piece body design
- **Added safety** with non-conductive ball bearings and driver
- **More than 100,000 key codes** made possible with linear, low-friction lock mechanism
- **Easy operation** with smooth key design and precision steel tumbler blades
- **Fast identification** with color-matched lock and key

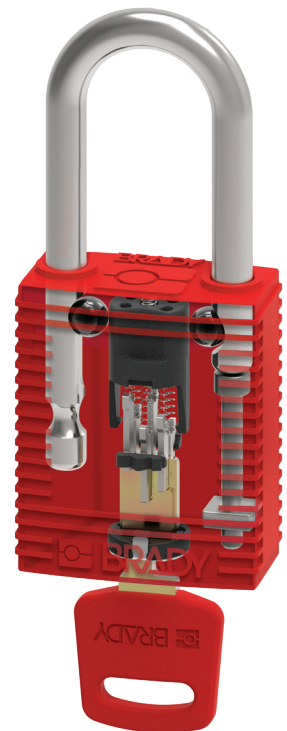

#### Traditional safety padlocks

- Pin tumbler lock mechanism
- Jagged key design
- Up to 15,000 key codes

## Get the best padlock for your application

It's all about options — and SafeKey Lockout Padlocks provide them. Choose from a variety of options to fit your specific application and facility needs. Each padlock includes one key with the flexibility to order more keys if needed.

### Nylon SafeKey Padlocks

- Ideal for electrical and general lockout applications
- Nylon body is lightweight with a durable, steel shackle option and a polymer plastic shackle option that's non-conductive and non-sparking
- Key-retaining lock feature
- 1.5 in. (38 mm) steel shackle

Color	Keyed Different	Keyed Different (6/Pack)	Keyed Alike (3/Pack)	Keyed Alike (6/Pack)
Red	NYL-RED-38ST-KD	NYL-RED-38ST-KD6PK	NYL-RED-38ST-KA3PK	NYL-RED-38ST-KA6PK
Green	NYL-GRN-38ST-KD	NYL-GRN-38ST-KD6PK	NYL-GRN-38ST-KA3PK	NYL-GRN-38ST-KA6PK
Orange	NYL-ORG-38ST-KD	NYL-ORG-38ST-KD6PK	NYL-ORG-38ST-KA3PK	NYL-ORG-38ST-KA6PK
Blue	NYL-BLU-38ST-KD	NYL-BLU-38ST-KD6PK	NYL-BLU-38ST-KA3PK	NYL-BLU-38ST-KA6PK
Yellow	NYL-YLW-38ST-KD	NYL-YLW-38ST-KD6PK	NYL-YLW-38ST-KA3PK	NYL-YLW-38ST-KA6PK
Brown	NYL-BRN-38ST-KD	NYL-BRN-38ST-KD6PK	NYL-BRN-38ST-KA3PK	NYL-BRN-38ST-KA6PK
White	NYL-WHT-38ST-KD	NYL-WHT-38ST-KD6PK	NYL-WHT-38ST-KA3PK	NYL-WHT-38ST-KA6PK
Purple	NYL-PRP-38ST-KD	NYL-PRP-38ST-KD6PK	NYL-PRP-38ST-KA3PK	NYL-PRP-38ST-KA6PK
Black	NYL-BLK-38ST-KD	NYL-BLK-38ST-KD6PK	NYL-BLK-38ST-KA3PK	NYL-BLK-38ST-KA6PK

### Compact Nylon SafeKey Padlocks

- Ideal for use in small spaces for electrical contractors, maintenance and electricians
- Extremely compact and lightweight design with non-conductive and non-sparking nylon body and polymer shackle
- 1.0 in (25 mm) plastic shackle

Color	Keyed Different	Keyed Different (6/Pack)	Keyed Alike (3/Pack)	Keyed Alike (6/Pack)
Red	CPT-RED-25PL-KD	CPT-RED-25PL-KD6PK	CPT-RED-25PL-KA3PK	CPT-RED-25PL-KA6PK
Green	CPT-GRN-25PL-KD	CPT-GRN-25PL-KD6PK	CPT-GRN-25PL-KA3PK	CPT-GRN-25PL-KA6PK
Orange	CPT-ORG-25PL-KD	CPT-ORG-25PL-KD6PK	CPT-ORG-25PL-KA3PK	CPT-ORG-25PL-KA6PK
Blue	CPT-BLU-25PL-KD	CPT-BLU-25PL-KD6PK	CPT-BLU-25PL-KA3PK	CPT-BLU-25PL-KA6PK
Yellow	CPT-YLW-25PL-KD	CPT-YLW-25PL-KD6PK	CPT-YLW-25PL-KA3PK	CPT-YLW-25PL-KA6PK
Brown	CPT-BRN-25PL-KD	CPT-BRN-25PL-KD6PK	CPT-BRN-25PL-KA3PK	CPT-BRN-25PL-KA6PK
White	CPT-WHT-25PL-KD	CPT-WHT-25PL-KD6PK	CPT-WHT-25PL-KA3PK	CPT-WHT-25PL-KA6PK
Purple	CPT-PRP-25PL-KD	CPT-PRP-25PL-KD6PK	CPT-PRP-25PL-KA3PK	CPT-PRP-25PL-KA6PK
Black	CPT-BLK-25PL-KD	CPT-BLK-25PL-KD6PK	CPT-BLK-25PL-KA3PK	CPT-BLK-25PL-KA6PK

### Aluminum SafeKey Padlocks

- Ideal for indoor and outdoor use and heavy-duty applications
- Aluminum padlock with steel shackle provides corrosion resistance
- 1.5 in. (38 mm) steel shackle

Color	Keyed Different	Keyed Different (6/Pack)	Keyed Alike (3/Pack)	Keyed Alike (6/Pack)
Red	ALU-RED-38ST-KD	ALU-RED-38ST-KD6PK	ALU-RED-38ST-KA3PK	ALU-RED-38ST-KA6PK
Green	ALU-GRN-38ST-KD	ALU-GRN-38ST-KD6PK	ALU-GRN-38ST-KA3PK	ALU-GRN-38ST-KA6PK
Orange	ALU-ORG-38ST-KD	ALU-ORG-38ST-KD6PK	ALU-ORG-38ST-KA3PK	ALU-ORG-38ST-KA6PK
Blue	ALU-BLU-38ST-KD	ALU-BLU-38ST-KD6PK	ALU-BLU-38ST-KA3PK	ALU-BLU-38ST-KA6PK
Yellow	ALU-YLW-38ST-KD	ALU-YLW-38ST-KD6PK	ALU-YLW-38ST-KA3PK	ALU-YLW-38ST-KA6PK
Brown	ALU-BRN-38ST-KD	ALU-BRN-38ST-KD6PK	ALU-BRN-38ST-KA3PK	ALU-BRN-38ST-KA6PK
Silver	ALU-SLV-38ST-KD	ALU-SLV-38ST-KD6PK	ALU-SLV-38ST-KA3PK	ALU-SLV-38ST-KA6PK
Purple	ALU-PRP-38ST-KD	ALU-PRP-38ST-KD6PK	ALU-PRP-38ST-KA3PK	ALU-PRP-38ST-KA6PK
Black	ALU-BLK-38ST-KD	ALU-BLK-38ST-KD6PK	ALU-BLK-38ST-KA3PK	ALU-BLK-38ST-KA6PK

 **Contact your local Brady representative to learn more**

USA  
Customer Service: 1-888-272-3946  
Inside Sales: 1-888-311-0775  
[BradyID.com](http://BradyID.com)