


# SYLVANIA Luminaires

## Slim Downlight

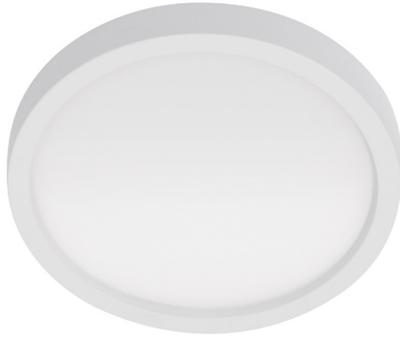


### Product Features

- Edge-lit LED technology for even, low glare illumination
- Self-adjusting springs for flush installation
- Low profile, seamless design to upgrade the space
- Directly mounts to j-box for low plenum applications

Catalog #	Type
Project	
Notes	
Date	
Prepared by	

### Dimensions

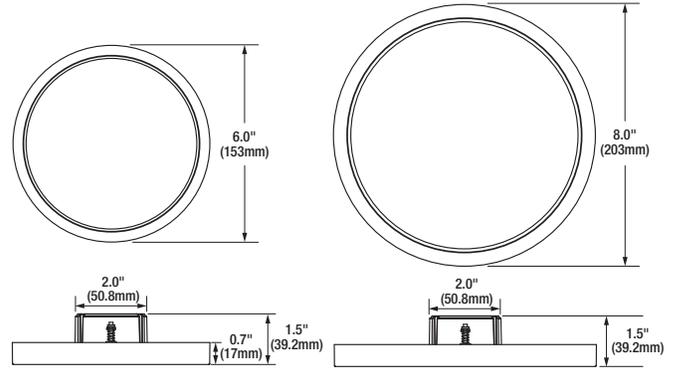

### Specifications

**Weight:** 6": 1.5lbs (0.6kg) 8": 2.0lbs (0.9kg)

**Construction:** Aluminum back plate with polycarbonate trim and lens. The standard finish is white.

**LED System:** LED system with a life rating of  $\geq 50,000$  hours at  $L_{70}$  @25°C. Luminaire efficacy up to 71 LPW.

**Electrical:** Offered in 10 and 14 Watts, the luminaire is designed to operate at 120-277V with driver on board. The power factor is  $\geq 90\%$  and THD is  $\leq 20\%$ .

**Dimming:** The driver is phase-cut dimmable (down to 10%).

**Color Characteristics:** CRI $>80$ ; CCT of 2700K, 3000K or 4000K.

**Optics:** White polycarbonate lens with edge-lit LED technology.

**Installation:** Luminaire mounts to recessed outlet box.

**Operating Temperature:** +14°F to +104°F (-10°C to +40°C).

**Listings:** cULus listed to UL1598 standards for damp locations.

**Warranty:** Standard 5-year luminaire warranty (LEDLUM001).

**Note:** Specifications subject to change without notice. IES files available online.



### Ordering Guide

Item Number:

SLMDNLR	1A	/	XXX	UNV	T	8	XX	/	XX	J	/	WH
Product Name	Generation		Wattage*	Voltage	Dimming	CRI	Color Temp (CCT)		Diameter	Mounting		Color/Finish
SLMDNLR	1A		010 = 10W 014 = 14W	UNV = 120-277V	T = Phase-cut (120V ONLY)	8 $\geq 80$	27 = 2700K 30 = 3000K 40 = 4000K		06 = 6 in 08 = 8 in	J = J-Box		WH = White

\*10W only available in 6in, 14W only available in 8in.

## Ordering Information

Item Number	Ordering Abbreviation	Power (W)	Input Voltage	Dimming**	CRI	Color Temp (CCT)	Size	Total Fixture Lumens	LPW*
60003	SLMDNLR1A/010UNVT827/06J/WH	10	120-277V	Phase-cut	>80	2700K	6"	700	70
60004	SLMDNLR1A/010UNVT830/06J/WH	10	120-277V	Phase-cut	>80	3000K	6"	750	75
60005	SLMDNLR1A/010UNVT840/06J/WH	10	120-277V	Phase-cut	>80	4000K	6"	800	80
60058	SLMDNLR1A/014UNVT827/08J/WH	14	120-277V	Phase-cut	>80	2700K	8"	980	70
60057	SLMDNLR1A/014UNVT830/08J/WH	14	120-277V	Phase-cut	>80	3000K	8"	1050	75
60056	SLMDNLR1A/014UNVT840/08J/WH	14	120-277V	Phase-cut	>80	4000K	8"	1120	80

\*LPW per LM79 report  
\*\*Only dimmable at 120V

LEDVANCE LLC  
200 Ballardvale Street  
Wilmington, MA 01887 USA  
Phone 1-800-LIGHTBULB (1-800-544-4828)  
[www.sylvania.com](http://www.sylvania.com)

SYLVANIA and LEDVANCE are registered trademarks.  
All other trademarks are those of their respective owners.  
Licensee of product trademark SYLVANIA in general lighting.  
Specifications subject to change without notice.

 /sylvania  /sylvania

