



Produktname | *Product name*: IN-Car Charger 240C
 Artikelnummer | *Part Number*: 1000-0021
 Ersteller / Datum | *Creator / Date*: DE / 26.10.2017

Version	Change	Date	Name
VA	--- (Preliminary)	XX.XX.XXXX	XX


Template name: USB-cable , Template version: V0

Technische Daten des Adapters / technical data of the adapter:



Eingang / Primär:		<i>input / primary:</i>	
Spannung	12-24V DC	<i>voltage</i>	12-24V DC
Strom	max. 2100 mA	<i>current</i>	max. 2100 mA
Ausgang / Sekundär:		<i>output / secondary:</i>	
Spannung	5.0V DC $\pm 5\%$	<i>voltage</i>	5.0V DC $\pm 5\%$
Gesamt Strom (USB Type A)	max. 4000mA (max. 1000mA)	<i>total current</i> <i>USB Type A</i>	max. 4000mA (max. 1000mA)
(USB Type C)	(max. 3000mA)	<i>USB Type C</i>	(max. 3000mA)
Leistung	20W	<i>power</i>	20W
USB Port	1 x Type A USB 1 x Type C USB	<i>USB port</i>	1 x Type A USB 1 x Type C USB
USB Beschaltung	1 x Type A USB 1A 1 x Type C IC	<i>USB resistor network</i>	1 x Type A USB 1A 1 x Type C IC
Schutzbeschaltung	Kurzschlusschutz Überspannungsschutz Verpolschutzschutz	<i>protection circuit</i>	<i>short circuit protection</i> <i>over voltage protection</i> <i>wrong polarity protection</i>
Gehäuse	KFZ-Steckergehäuse, schwarz	<i>case</i>	<i>car lighter plug</i> <i>black</i>
Gehäusematerial	UL94V-0	<i>housing material</i>	UL94V-0
Betriebstemperatur	0°C.....+40°C	<i>operating temperature</i>	0°C.....+40°C
Approbation	CE	<i>approval</i>	CE
Gewicht ohne Verpackung	22g	<i>weight without package</i>	22g
Verpackung	Farbige Faltschachtel	<i>package</i>	<i>color box</i>

2D Zeichnung / Drawing:

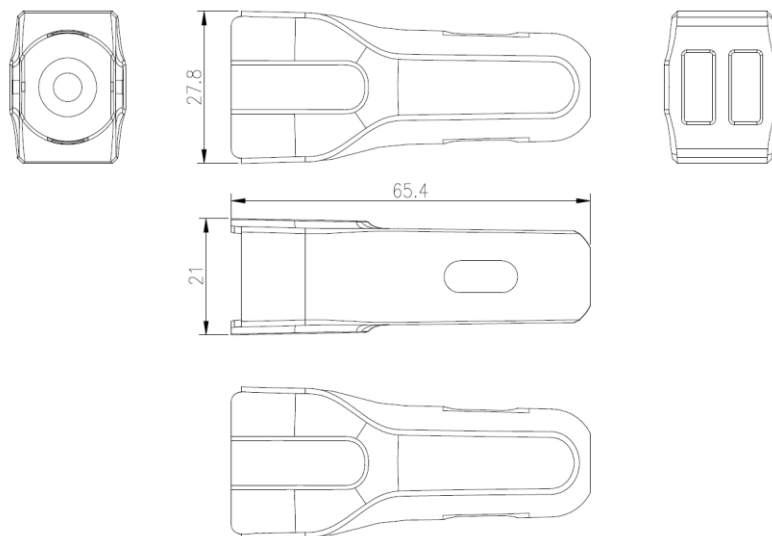

Allowable deviation / general tolerances DIN ISO 2768-c