






OYN-X | 5MP 4-in-1 EYEBALL CAMERA



SPECIFICATION	5X-EYE-FG24/FW24
Camera	
Image Sensor	1/2.5" CMOS 5MP (2688 x 1944) Image Sensor
Signal System	PAL / NTSC
Active Pixels	2688 x 1944
Lens	3.6mm MP Lens
Angle of View	H: 97°
Horizontal Resolution	5MP @ 20fps / 12.5fps, 4MP @ 25fps / 12.5fps (NRT- ON/ OFF). (Confirm your selection through the OSD Menu on the DVR screen)
Brightness	1-100 (Default: 32, Adjust the brightness value according to the installed location)
Exit	Save & Exit / Exit / Reset
Min Illumination	0 Lux (IR ON - IR-cut technology)
Menu	UTC Control
Language	ENG / CHN / GER / FRA / ITA / SPA / POL / RUS / POR / NED / TUR / JPN
Auto Electronic Shutter	PAL:1/50 - 1/100,000 sec, NTSC:1/60 - 1/100,000 sec
Backlight	BLC / HSBLC / OFF
White Balance	ATW / AWC->SET / Indoor / Outdoor / Manual
Mirror	Mirror / V-Flip / Rotate / Off
Day & Night	Auto / Colour / B&W / Ext
DNR	2-DNR, Off / Low / Middle / High
D-WDR	ON / OFF / AUTO
Video Output	CVBS / CVI / AHD / TVI **Factory Default is TVI (Confirm your selection through the OSD Menu on the DVR screen)
Auto Gain Control	Built-in
Power Supply	DC12V \pm 10%
Current Consumption	70 mA(IR OFF), 230 mA(IR ON)
IR Led	24 pcs
IR Distance in Effect	20 - 25M
IP Rating	IP66
Storage / Operating Temp.	-50°C ~ +90°C / -30°C ~ +70°C
Dimension / Weight	Φ93 x 80mm / 350g

DIAGRAM Unit (mm)

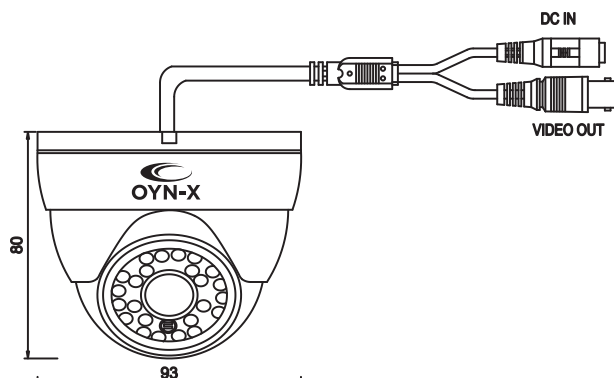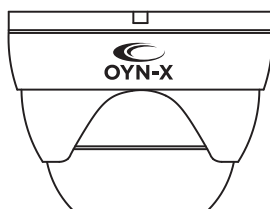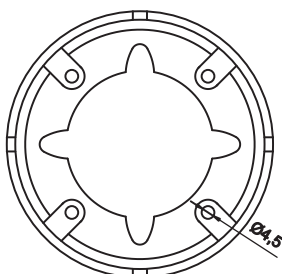

For further information on our products visit our website www.oyn-x.com, email: distribution@adata.co.uk, sales Line: (023 92 488366).