

Display Adapters & Convertors

DisplayPort Adapters

Part No: 2409ED

This high quality adaptor supports the link from a PC featuring the DisplayPort interface to a DVI display.

Specification

<ul style="list-style-type: none"> ● Input DisplayPort M Max 1920x1200 	<ul style="list-style-type: none"> ● Output VGA F Max 1920x1200
<ul style="list-style-type: none"> ● Operating Frequency Vertical Frequency Range Bandwidth 	<ul style="list-style-type: none"> 50/60Hz 162Mhz 225MHz/2.25 Gbps / channel
<ul style="list-style-type: none"> ● Physical Size (LxWxD) Weight (Net) Colour Connector 	<ul style="list-style-type: none"> 45 x 45 x 15mm 30g Black Nickel Plated
<ul style="list-style-type: none"> ● Operational Operating Temperature Operating Humidity Storage Temperature Storage Humidity 	<ul style="list-style-type: none"> 0 °C to +55 °C 10% to 85% RH (no condensation) 0 °C to +70 °C 5% to 90% RH (no condensation)
<ul style="list-style-type: none"> ● Power Requirement 	<ul style="list-style-type: none"> No external power needed
<ul style="list-style-type: none"> ● Regulatory Approvals 	<ul style="list-style-type: none"> CE, FCC, RoHS




Features & Benefits

- V1.2 available with 4K2K support
- V1.2 Compatible for 3+ Monitors
- V1.1 with resolutions up to 1920x1200
- Support Video Bandwidth to 10.8Gbps
- Support Full DisplayPort Link 20 Pin
- With latch-lock

Display Adapters & Convertors

DisplayPort Adapters

Part No: 2409ED

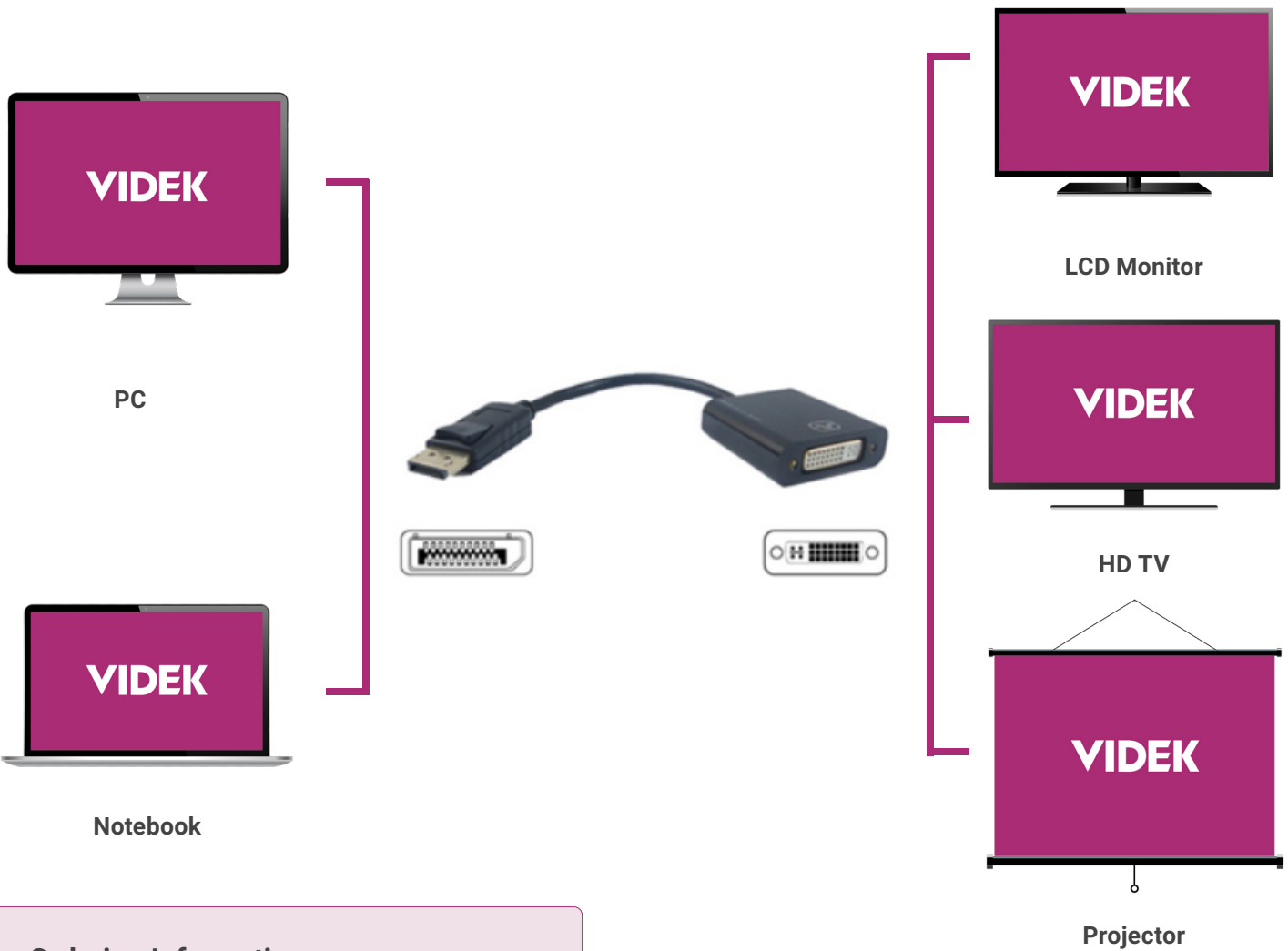

Ordering Information

- **Part No:**
2409ED
- **Product Description:**
VIDEK DisplayPort Plug to DVI Socket
Adaptor - Black