

Display Adapters & Convertors

DisplayPort Adapters

Part No: 2409EHD

This high quality adaptor supports the link from a PC featuring the DisplayPort interface to a HDMI display.

Specification

● Input	Output
DisplayPort M Max 1920x1200	HDMI F Max 1920x1200
● Operating Frequency	
Vertical Frequency Range	50/60Hz 162Mhz
Bandwidth	225MHz/2.25 Gbps / channel
● Physical	
Size (LxWxD)	45 x 45 x 15mm
Weight (Net)	30g
Colour	Black
Connector	Nickel Plated
● Operational	
Operating Temperature	0 °C to +55 °C
Operating Humidity	10% to 85% RH (no condensation)
Storage Temperature	0 °C to +70 °C
Storage Humidity	5% to 90% RH (no condensation)
● Power Requirement	No external power needed
● Regulatory Approvals	CE, FCC, RoHS




Features & Benefits

- Complies with DisplayPort 1.1 standard
- Supports HDMI resolution up to 1080P
- Supports extend/mirror display
- Easy to use adapter, no software required.
- POWERED from DisplayPort
- Plug-n-Play

Display Adapters & Convertors

DisplayPort Adapters

Part No: 2409EHD

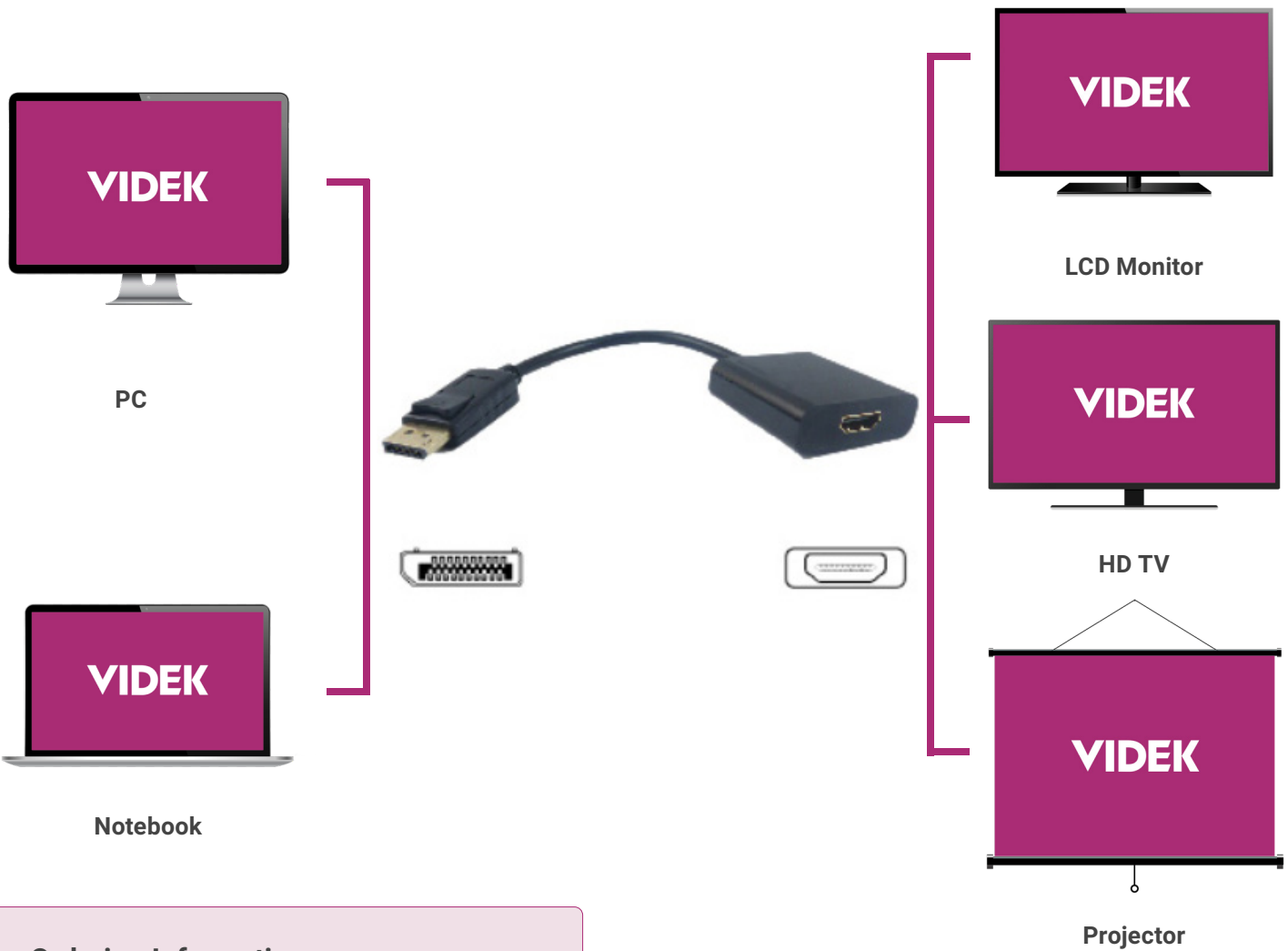

Ordering Information

- **Part No:**
2409EHD
- **Product Description:**
VIDEK DisplayPort Plug to HDMI Socket
Adaptor 1920 x 1200 60HZ - Black